



TOP VIEW

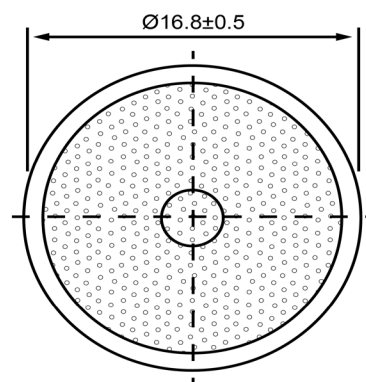

SIDE VIEW

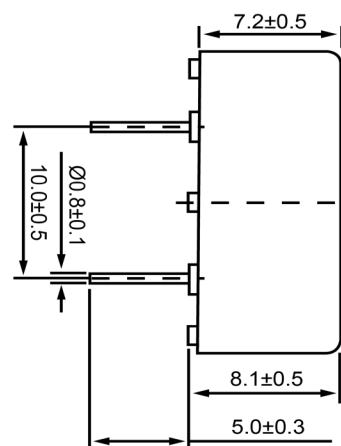

## Specifications

Description	Value	Unit
Technology	Piezo	
Resonant Frequency	4,000	(Hz)
Rated Voltage	9	(V)
SPL @ 10cm	80	(dBA)
Capacitance	10,500	(pF)
Mount Type	Thru Hole	
Voltage Range	1 ~ 30	(V)
Max Rated Current	7	(mA)
Housing Material	PBT	
Operating Temperature	-20 ~ +70	°C
Storage Temperature	-20 ~ +70	°C
Weight	3	(g)

## Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



DB UNLIMITED

Piezo Transducer

## Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S

TP164009-2

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP164009-2](#)