



| | | |
|--|----------|-----------|
| Part Number: | DRAWN | 4/21/2017 |
| | CJ | |
| | CHECKED | 4/21/2017 |
| Description: | P.D. | |
| | APPROVED | 4/21/2017 |
| | C.E. | |
| This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com | | |


Top View

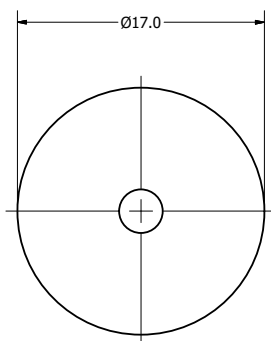

Side View

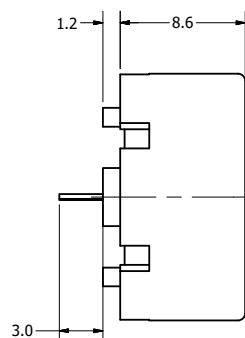

Bottom View

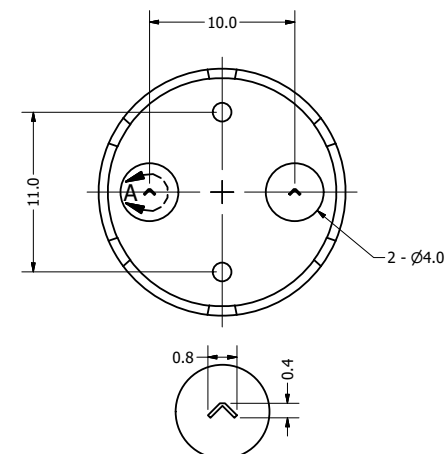

DETAIL A
SCALE 10 : 1

| Items | Specifications | Conditions |
|-----------------------|----------------|-------------|
| Sound Pressure Level | ≥ 78 | dB (@ 10cm) |
| Resonant Frequency | 2,000 | Hz |
| Rated Voltage | 9 | Vp-p |
| Voltage Range | 1 ~ 25 | V |
| Capacitance | 25,000 | pF |
| Max. Rated Current | 7 | mA |
| Storage Temperature | -40 ~ +85 | °C |
| Operating Temperature | -40 ~ +85 | °C |
| Connection Method | PC Pins | |
| Mount Type | Thru Hole | |
| Housing Material | NORYL | |
| Weight | 1 | g |

REVISION HISTORY

| REV | DESCRIPTION | DATE | APPROVED |
|-----|---|------------|----------|
| | Released from Engineering | 10/21/2013 | J.S. |
| 1 | Update operating temp, new drawing template | 4/24/2017 | C.E. |

NOTES

- 1) All dimensions are in mm unless otherwise noted
- 2) All tolerances are ± 0.5 mm unless otherwise noted
- 3) All parts meet RoHS
- 4) Subject to change or redrawn without notice

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP172009-1](#)