




TOP VIEW

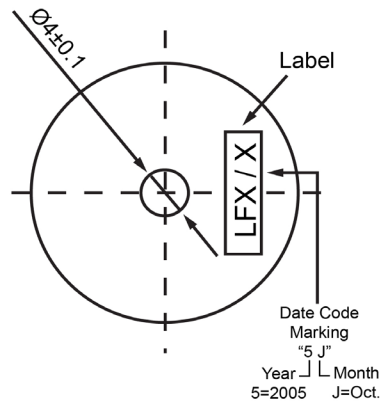

SIDE VIEW

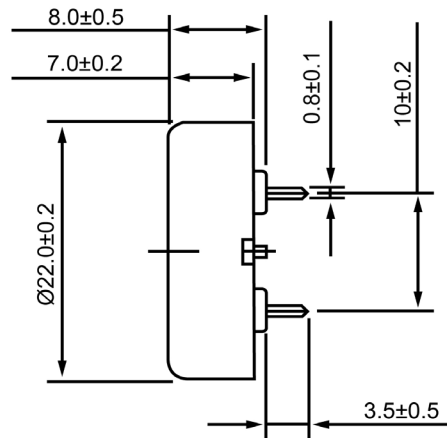

BOTTOM VIEW

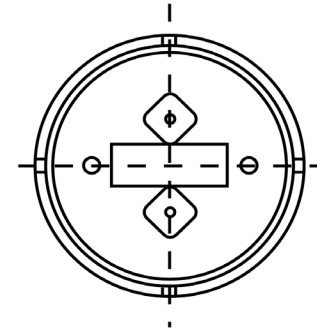

Specifications

Description	Value	Unit
Technology	Piezo	
Resonant Frequency	4,000	(Hz)
Rated Voltage	3	(V)
SPL @ 10cm	80	(dBA)
Capacitance	15,000	(pF)
Mount Type	Thru Hole	
Voltage Range	1 ~ 40	(V)
Max Rated Current	5	(mA)
Housing Material	PBT	
Operating Temperature	- 30 ~ + 70	°C
Storage Temperature	- 30 ~ + 70	°C
Weight	3	(g)

Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



Revision History

Version	Description			Date	Approved
1	Released from Engineering			12/4/2013	J.S
Drawn by	Date	Checked by	Date	Approved by	Date
A.B.	12/3/2013	C.E.	12/4/2013	J.S	12/4/2013

Piezo Transducer

TP224003-2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP224003-2](#)