




TOP VIEW

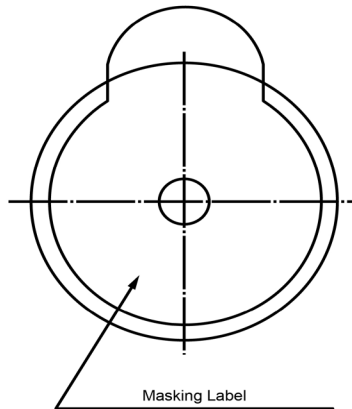

SIDE VIEW (1)

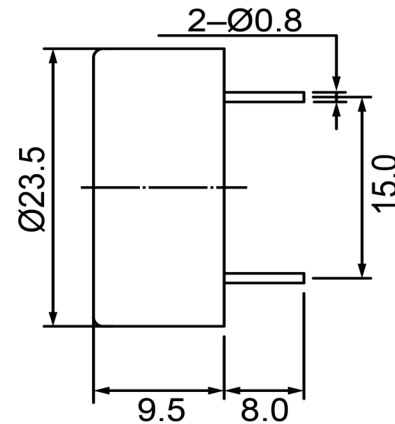

SIDE VIEW (2)

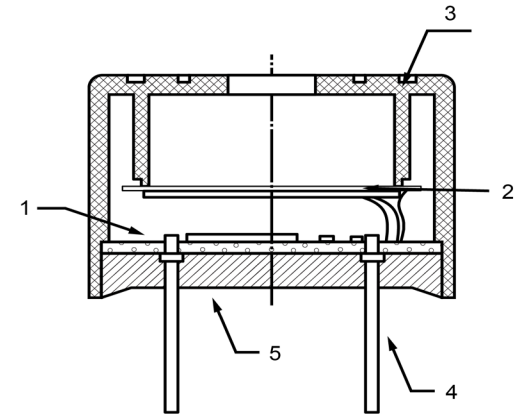

Specifications

Description	Value	Unit
Technology	Piezo	
Resonant Frequency	3,400	(Hz)
Rated Voltage	12	(V)
SPL @ 10cm	95	(dBA)
Mount Type	Thru Hole	
Voltage Range	3 ~ 20	(V)
Max Rated Current	10	(mA)
Housing Material	NORYL	
Operating Temperature	-20 ~ +70	°C
Storage Temperature	-30 ~ +80	°C
Weight	3	(g)

Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



DB UNLIMITED

Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S
					</

Piezo Transducer

TP233412-1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP233412-1](#)