





DB UNLIMITED

Part Number:	DRAWN	11/2/2023
	CJ	
	CHECKED	11/6/2023
Description:	P.D.	
	APPROVED	11/6/2023
Piezo Transducer		J.S.
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


Top View

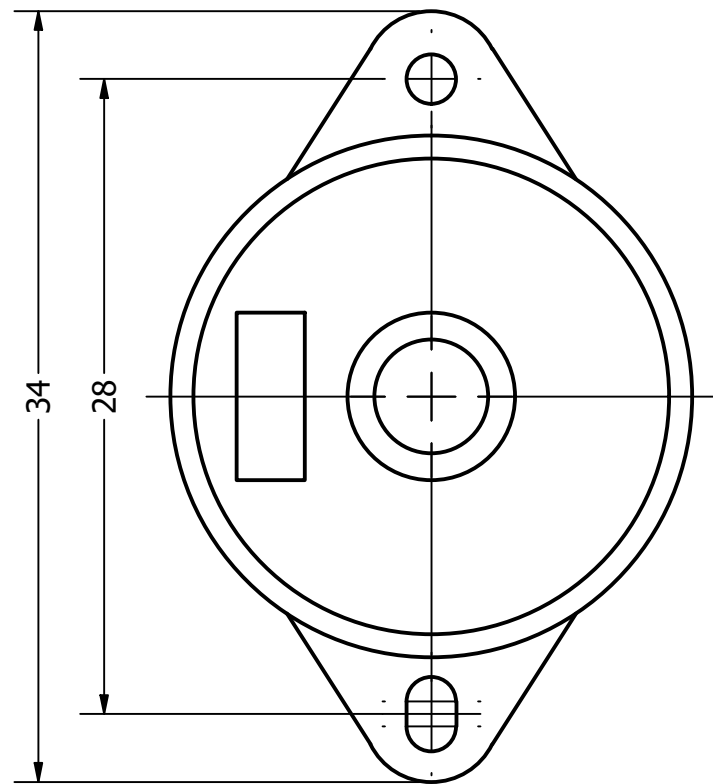

Side View

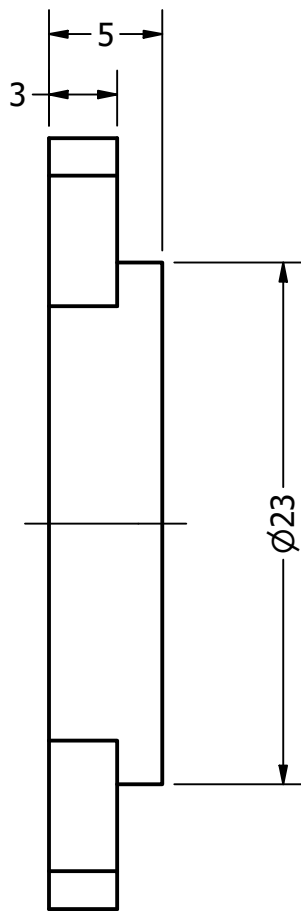

Bottom View

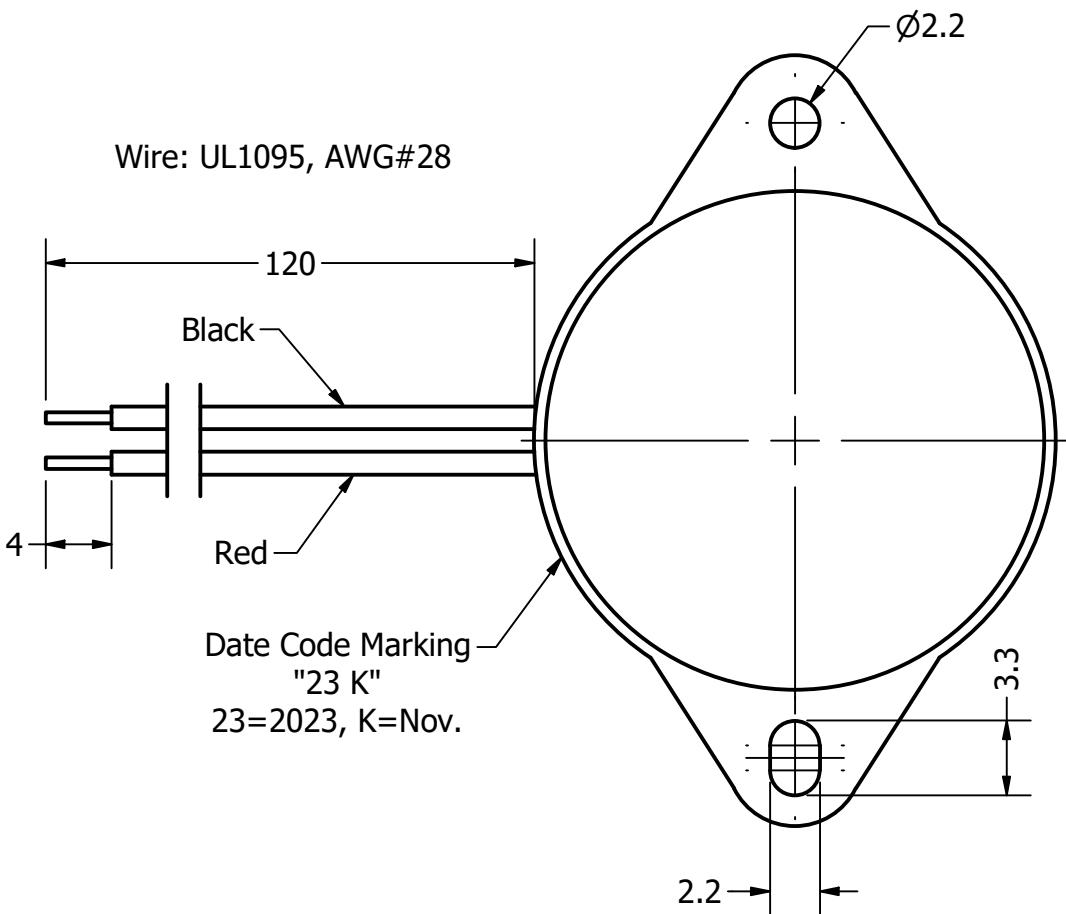

Items	Specifications	Conditions				
Min. Sound Pressure Level	89	dB (@ 10cm)				
Resonant Frequency	4,000	Hz				
Rated Voltage	12	V				
Voltage Range	1 ~ 40	V				
Capacitance	24,000	pF				
Max. Rated Current	7	mA				
Storage Temperature	-20 ~ +60	°C				
Operating Temperature	-20 ~ +60	°C				
Connection Method	Lead Wires					
Mount Type	Flange Mount					
Housing Material	ABS					
Weight	2	g				

REVISION HISTORY			
REV	DESCRIPTION	DATE	APPROVED
	Released from Engineering	10/21/2013	J.S.
1	Updated to new template	11/6/2023	P.D.

NOTES	
1) All dimensions are in mm unless otherwise noted	
2) All tolerances are ± 0.5 mm unless otherwise noted	
3) All parts meet RoHS	
4) Subject to change or redrawn without notice	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP234012-1](#)