



TOP VIEW

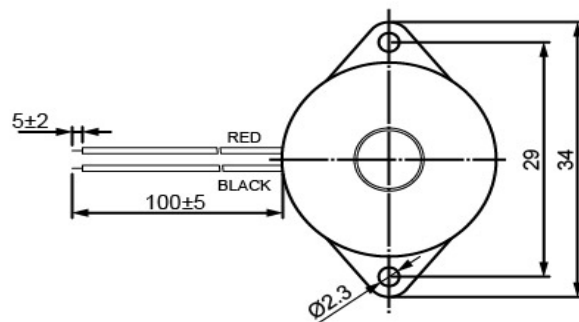

SIDE VIEW

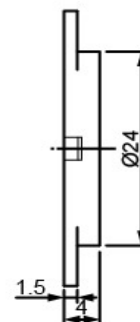

Specifications

Description	Value	Unit
Technology	Piezo	
Resonant Frequency	5,500	(Hz)
Rated Voltage	15	(V)
SPL @ 10cm	90	(dBA)
Capacitance	18,000	(pF)
Mount Type	Flange	
Voltage Range	1 ~ 30	(V)
Max Rated Current	8	(mA)
Housing Material	NORYL	
Operating Temperature	-30 ~ +70	°C
Storage Temperature	-40 ~ +85	°C
Weight	1.9	(g)

Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



DB UNLIMITED

Piezo Transducer

Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S
Drawn by	Date	Checked by	Date	Approved by	Date
A.B.	10/21/2013	C.E.	10/21/2013	J.S	10/21/2013

TP245515-2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP245515-2](#)