




TOP VIEW

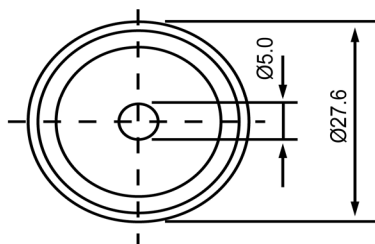


SIDE VIEW

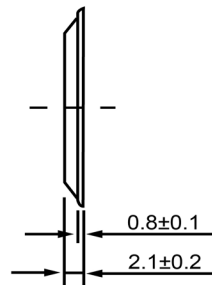

BOTTOM VIEW

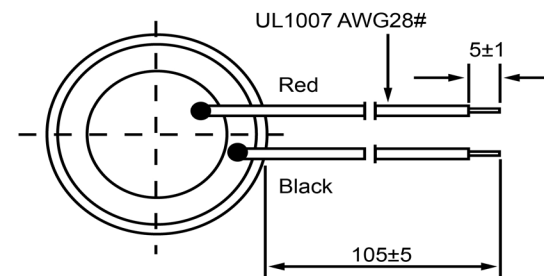

Specifications			Notes	Revision History					
Description	Value	Unit		Version	Description		Date	Approved	
Technology	Piezo		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S	
Resonant Frequency	4,200	(Hz)							
Rated Voltage	9	(V)							
SPL @ 10cm	85	(dBA)							
Capacitance	35,000	(pF)							
Mount Type	Flush								
Voltage Range	1 ~ 40	(V)							
Max Rated Current	7	(mA)							
Housing Material	Aluminum								
Operating Temperature	-20 ~ +80	°C							
Storage Temperature	-30 ~ +80	°C							
Weight	2	(g)							



DB UNLIMITED

Piezo Transducer

Drawn by	Date	Checked by	Date	Approved by	Date
A.B.	10/21/2013	C.E.	10/21/2013	J.S	10/21/2013

TP274209-1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP274209-1](#)