



Part Number:	DRAWN	5/16/2016
	CJ	
	CHECKED	5/18/2016
Description:	P.D.	
	APPROVED	5/18/2016
	J.S.	
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		


Top View

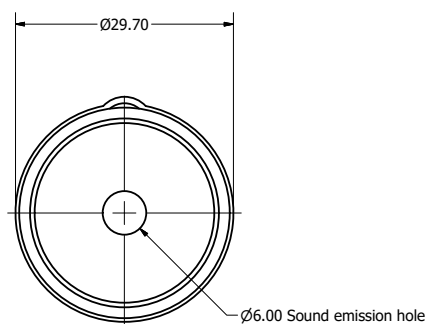

Side View

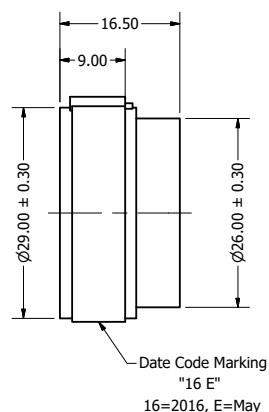

Bottom View

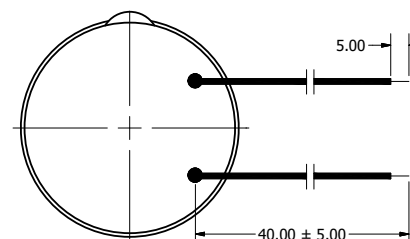

Items	Specifications	Conditions				
Sound Pressure Level	109	dB (@ 10cm)				
Resonant Frequency	3,400	Hz				
Rated Voltage	9	V	REV	DESCRIPTION	DATE	APPROVED
Voltage Range	9 ~ 28	V		Released from Engineering	10/21/2013	J.S.
Capacitance	25,000	pF (@ 120 Hz)	1	Updated to new template	5/18/2016	J.S.
Max. Rated Current	180	mA	2	Corrected SPL	5/18/2017	C.E.
Storage Temperature	-30 ~ +70	°C				
Operating Temperature	-20 ~ +60	°C				
Connection Method	Lead Wires					
Mount Type	Flush Mount					
Housing Material	ABS					
Weight	8	g				

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP293409-1](#)