




# TOP VIEW

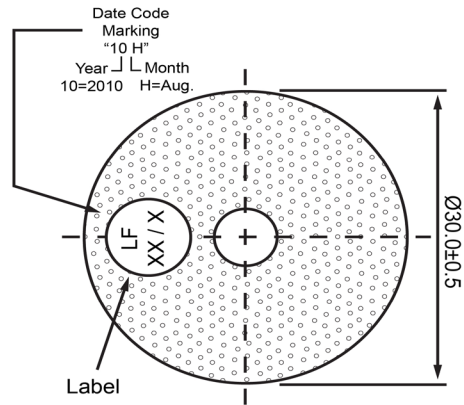

# SIDE VIEW

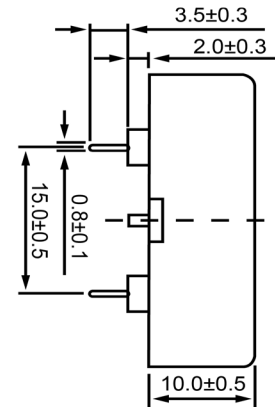

Specifications			Notes	Revision History							
Description	Value	Unit		Version	Description		Date	Approved			
Technology	Piezo		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S			
Resonant Frequency	2,500	(Hz)									
Rated Voltage	3	(V)									
SPL @ 10cm	90	(dBA)									
Capacitance	25,000	(pF)									
Mount Type	Thru Hole										
Voltage Range	1 ~ 30	(V)									
Max Rated Current	3	(mA)									
Housing Material	PBT										
Operating Temperature	-20 ~ +70	°C									
Storage Temperature	-20 ~ +70	°C									
Weight	6	(g)									
 DB UNLIMITED			Piezo Transducer			TP302505-1					
			Drawn by		Date		Checked by		Date		Approved by
A.B.		10/21/2013		C.E.		10/21/2013		J.S		10/21/2013	

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP302505-1](#)