




TOP VIEW

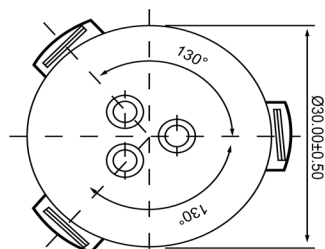

SIDE VIEW

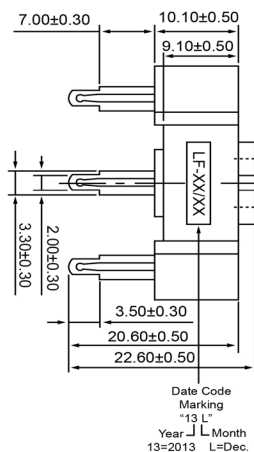

BOTTOM VIEW

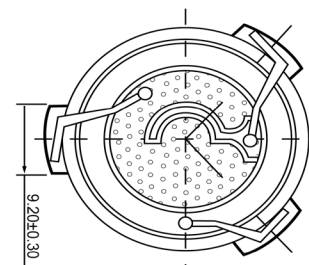

Specifications

Description	Value	Unit
Technology	Piezo	
Resonant Frequency	2,700	(Hz)
Rated Voltage	12	(V)
SPL @ 10cm	75	(dBA)
Capacitance	30,000	(pF)
Mount Type	Thru Hole	
Voltage Range	1.5 ~ 24	(V)
Max Rated Current	75	(mA)
Housing Material	PBT	
Operating Temperature	-20 ~ +105	°C
Storage Temperature	-30 ~ +105	°C
Weight	5	(g)

Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



DB UNLIMITED

Piezo Transducer

Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S

TP302712-1

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP302712-1](#)