




TOP VIEW

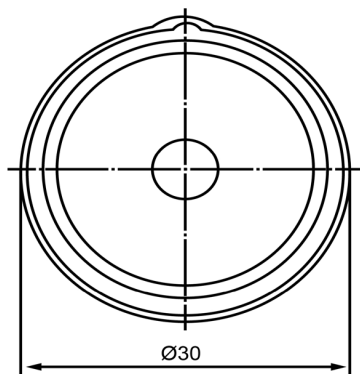

SIDE VIEW

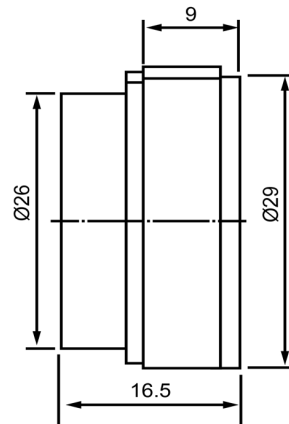

BOTTOM VIEW

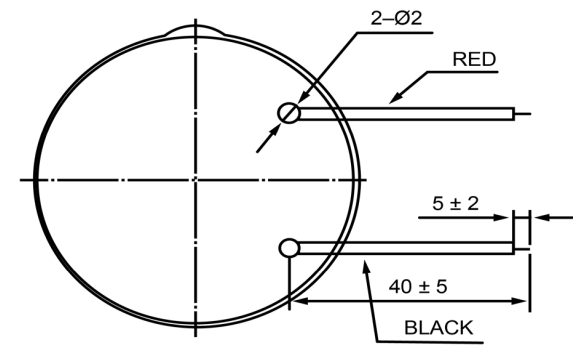

## Specifications

Description	Value	Unit
Technology	Piezo	
Resonant Frequency	3,400	(Hz)
Rated Voltage	9	(V)
SPL @ 10cm	90	(dBA)
Capacitance	25,000	(pF)
Mount Type	Flush Mount	
Voltage Range	3 ~ 28	(V)
Max Rated Current	5	(mA)
Housing Material	ABS	
Operating Temperature	-20 ~ +60	°C
Storage Temperature	-30 ~ +70	°C
Weight	8	(g)

## Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



DB UNLIMITED

Piezo Transducer

## Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S
Drawn by	Date	Checked by	Date	Approved by	Date
A.B.	10/21/2013	C.E.	10/21/2013	J.S	10/21/2013

TP303409-1

Additional considerations can be found at [www.dbunlimitedco.com/technical-articles](http://www.dbunlimitedco.com/technical-articles).

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP303409-1](#)