




TOP VIEW

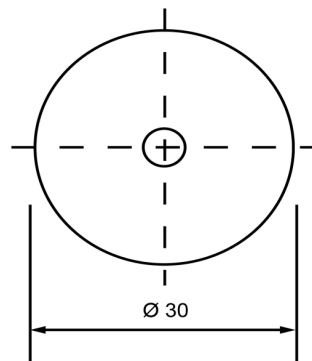

SIDE VIEW

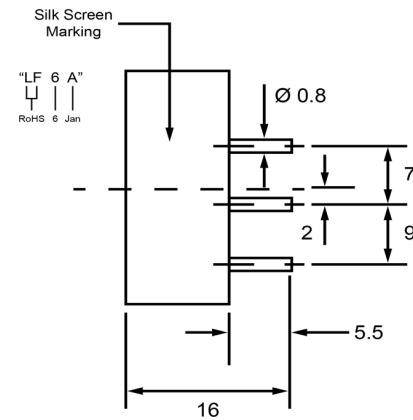

Specifications			Notes	Revision History							
Description	Value	Unit		Version	Description		Date	Approved			
Technology	Piezo		1) All dimensions are in mm unless otherwise noted 2) All parts meet RoHS	1	Released from Engineering		10/21/2013	J.S			
Resonant Frequency	3,600	(Hz)									
Rated Voltage	12	(V)									
SPL @ 10cm	88	(dBA)									
Mount Type	Thru Hole										
Voltage Range	3 ~ 20	(V)									
Max Rated Current	10	(mA)									
Housing Material	NORYL										
Operating Temperature	-30 ~ +70	°C									
Storage Temperature	-40 ~ +80	°C									
Weight	5	(g)									
			 DB UNLIMITED	Drawn by			Date	Checked by	Date	Approved by	Date
				A.B.			10/21/2013	C.E.	10/21/2013	J.S	10/21/2013
			Piezo Transducer					TP303612-1			

Additional considerations can be found at www.dbunlimitedco.com/technical-articles.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP303612-1](#)