



TOP VIEW

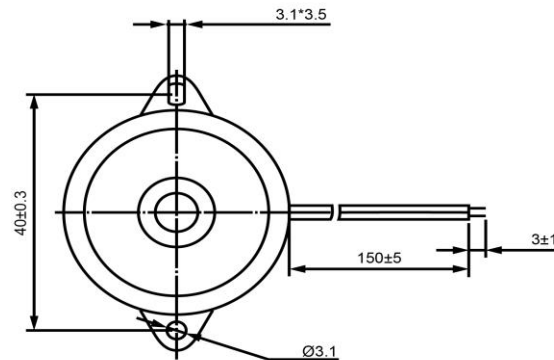

SIDE VIEW

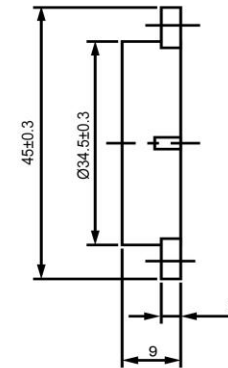

Specifications

Description	Value	Unit
Technology	Piezo	
Resonant Frequency	1,100	(Hz)
Rated Voltage	10	(V)
SPL @ 10cm	85	(dBA)
Capacitance	50,000	(pF)
Mount Type	Flange Mount	
Voltage Range	1 ~ 30	(V)
Max Rated Current	9	(mA)
Housing Material	ABS	
Operating Temperature	-20 ~ +60	°C
Storage Temperature	-30 ~ +70	°C
Weight	5	(g)

Notes

- 1) All dimensions are in mm unless otherwise noted
- 2) All parts meet RoHS



DB UNLIMITED

Piezo Transducer

Revision History

Version	Description			Date	Approved
1	Released from Engineering			10/21/2013	J.S

TP341110-1

Additional considerations can be found at www.dbunlimitedco.com/technical-articles.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP341110-1](#)