
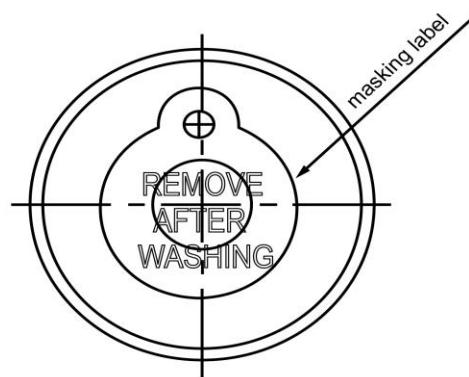
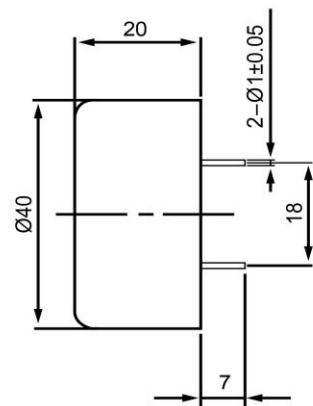


TOP VIEW**SIDE VIEW****BOTTOM VIEW****Specifications**

Description	Value	Unit
Technology	Piezo	
Resonant Frequency	3,200	(Hz)
Rated Voltage	12	(V)
SPL @ 10cm	105	(dBA)
Mount Type	Thru Hole	
Voltage Range	1 ~ 30	(V)
Max Rated Current	15	(mA)
Housing Material	NORYL	
Operating Temperature	-30 ~ +70	°C
Storage Temperature	-40 ~ +85	°C
Weight	1	(g)

Notes

- 1) All dimensions are in mm unless otherwise noted
2) All parts meet RoHS

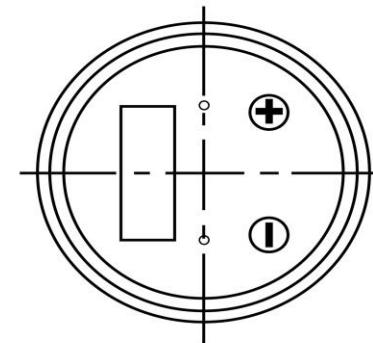

DB UNLIMITED

Piezo Transducer

Version	Description		Date	Approved
1	Released from Engineering		10/21/2013	J.S
Drawn by	Date	Checked by	Date	Approved by
A.B.	10/21/2013	C.E.	10/21/2013	J.S
				10/21/2013

TP403212-1Additional considerations can be found at www.dbunlimitedco.com/technical-articles.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[TP403212-1](#)