





DB UNLIMITED

Part Number:  SW201108-1	DRAWN CJ	3/10/2017
	CHECKED P.D.	10/6/2017
	APPROVED C.E.	10/6/2017
Description: Waterproof Dynamic Speaker		
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at <a href="http://www.dbunlimitedco.com">www.dbunlimitedco.com</a>		


Top View

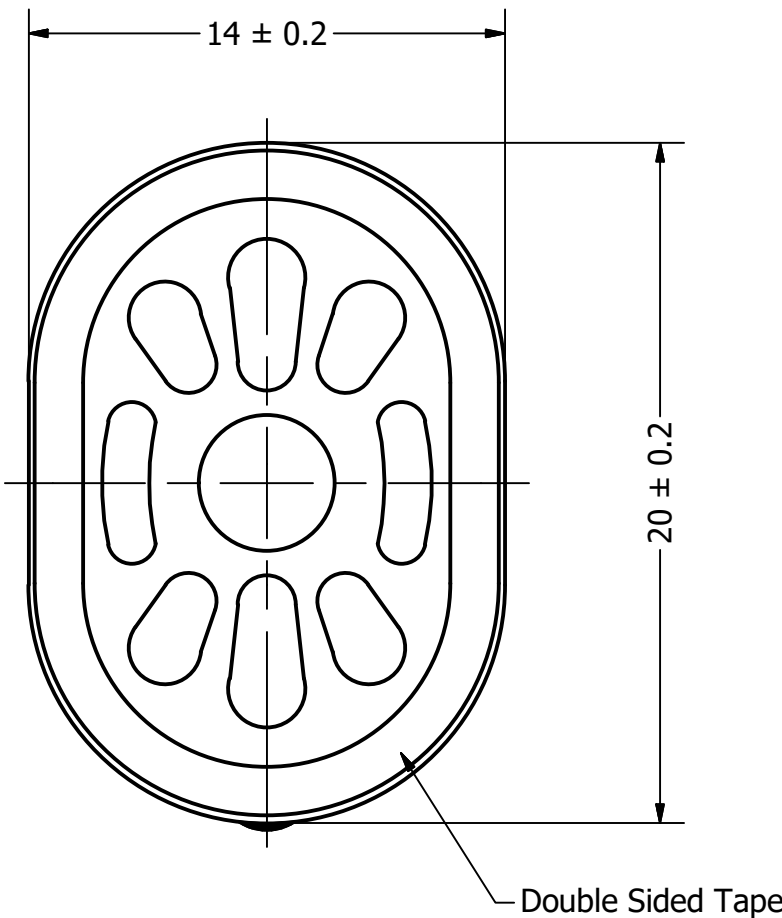

Side View

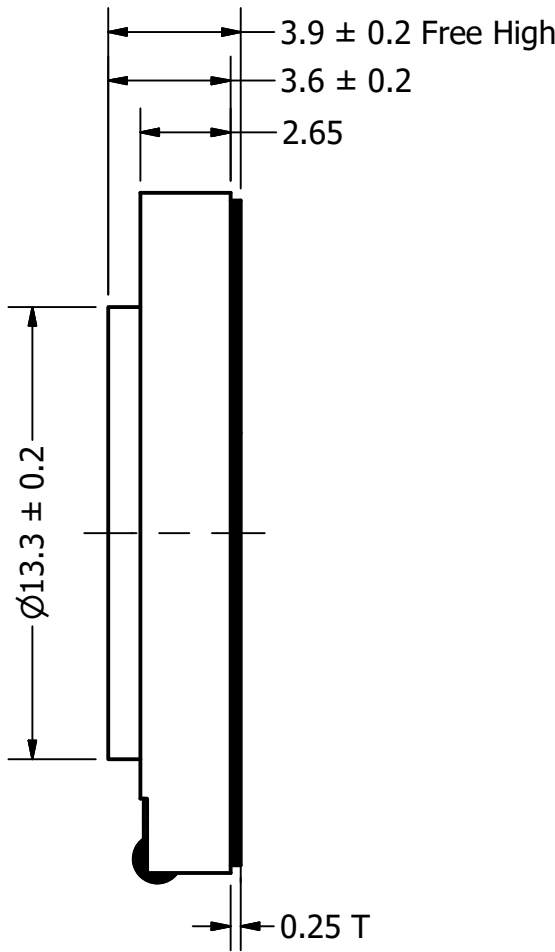

Bottom View

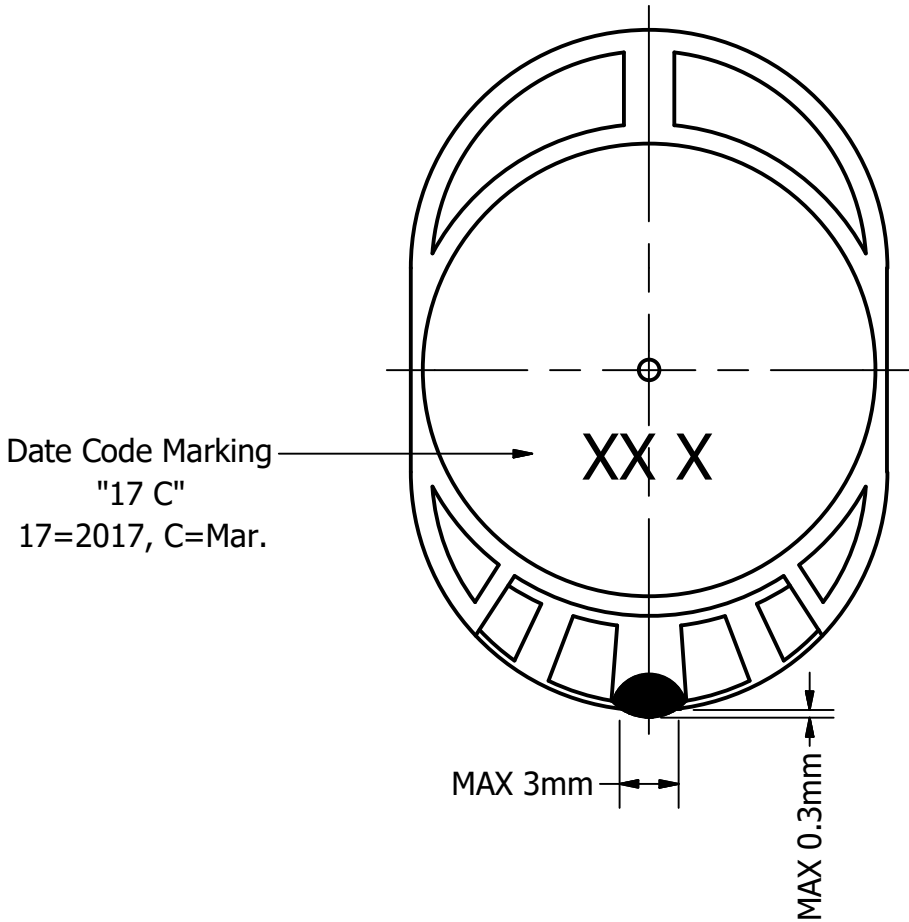

Items	Specifications	Conditions				
Sound Pressure Level	97	dB (@ 10cm), Avg.				
Resonant Frequency	1,100	Hz				
Frequency Range	1,100 ~ 10,000	Hz				
Nominal Power	0.8	W				
Max. Power	1.2	W				
Impedance	8	Ω				
Cone Material	Mylar					
Mount Type	Flush Mount					
IP Rating	IP67					
Storage Temperature	-40 ~ +85	°C				
Operating Temperature	-20 ~ +60	°C				
Weight	1.84	g				

REVISION HISTORY			
REV	DESCRIPTION	DATE	APPROVED
	Released from Engineering	10/6/2017	C.E.

NOTES	
1) All dimensions are in mm unless otherwise noted	
2) All tolerances are ± 0.3 mm unless otherwise noted	
3) All parts meet RoHS	
4) Subject to change or redrawn without notice	

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SW201108-1](#)