



Part Number:	DRAWN CJ	3/10/2017
	CHECKED P.D.	10/5/2017
	APPROVED C.E.	10/5/2017
Description: Waterproof Dynamic Speaker		
This document contains data proprietary to DB Unlimited. Any use or reproduction, in any form, without prior written permission of DB Unlimited is prohibited. All terms and conditions can be found at www.dbunlimitedco.com		

Top View

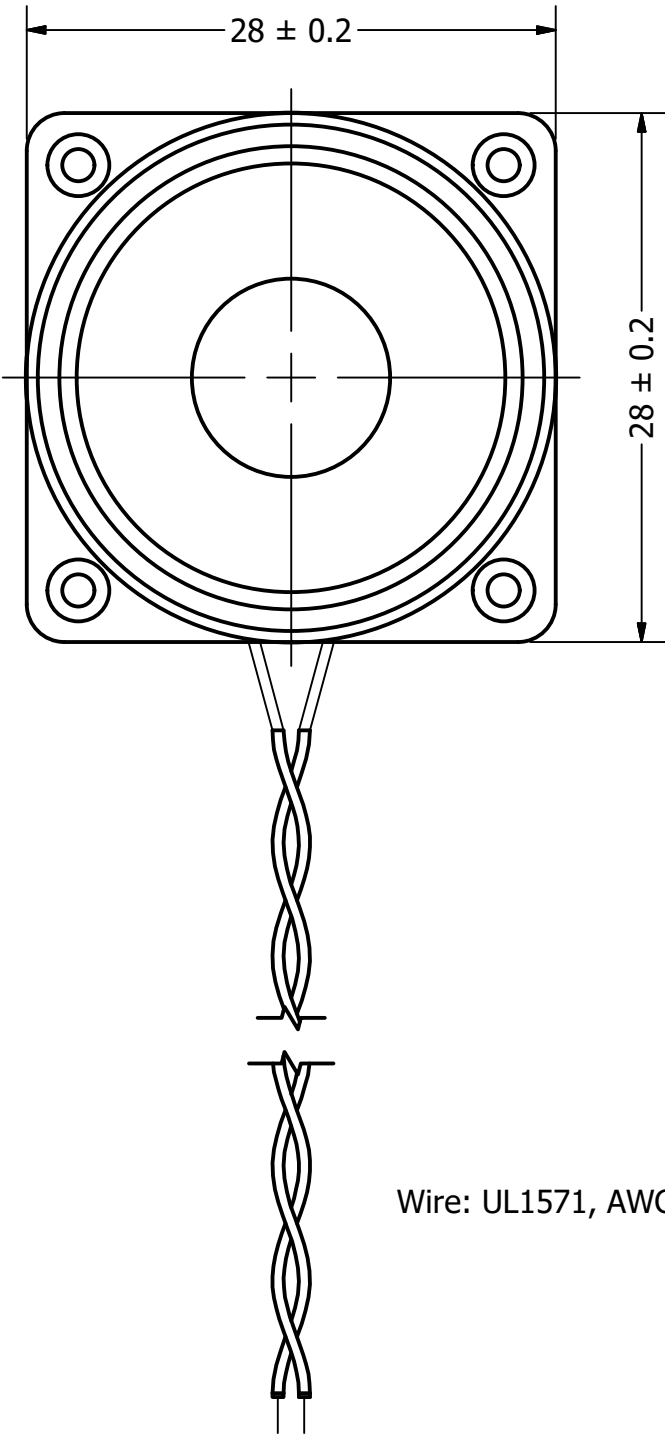


Wire: UL1571, AWG#32

Side View

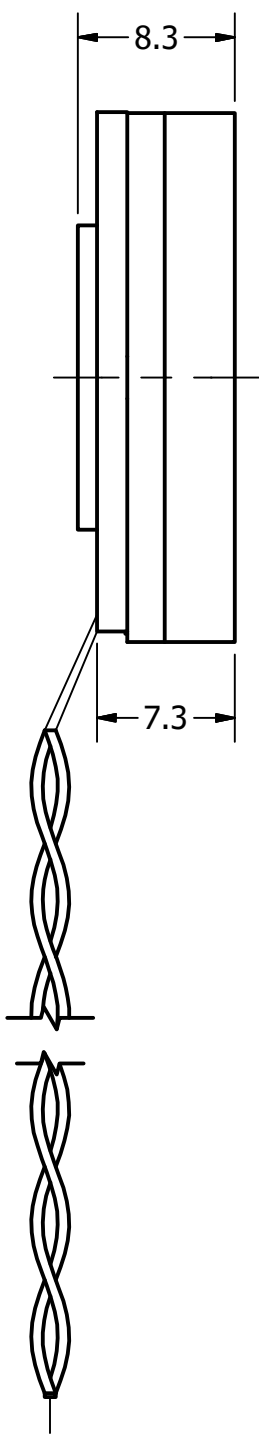

Bottom View

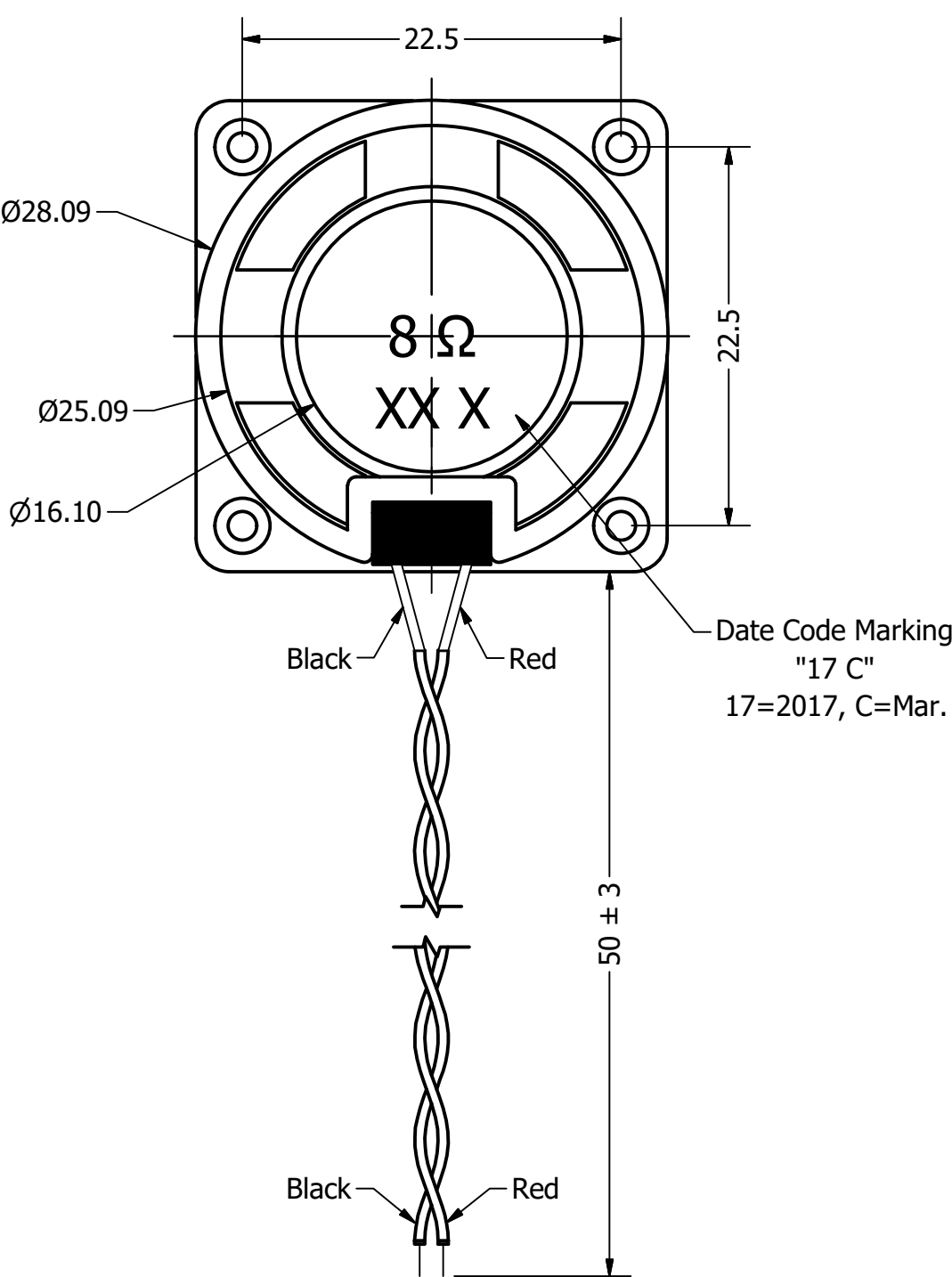

Items	Specifications	Conditions				
Sound Pressure Level	90	dB (@ 10cm), Avg.				
Resonant Frequency	400	Hz				
Frequency Range	400 ~ 10,000	Hz				
Nominal Power	1.5	W	REVISION HISTORY			
Max. Power	2	W	REV	DESCRIPTION	DATE	APPROVED
Impedance	8	Ω		Released from Engineering	10/5/2017	C.E.
Cone Material	Mylar		NOTES			
Mount Type	Frame Mount		1) All dimensions are in mm unless otherwise noted			
IP Rating	IP67		2) All tolerances are ± 0.3 mm unless otherwise noted			
Storage Temperature	-20 ~ +55	°C	3) All parts meet RoHS			
Operating Temperature	-20 ~ +55	°C	4) Subject to change or redrawn without notice			
Weight	7.3	g				

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[DB Unlimited:](#)

[SW280408-1](#)