






Order Code	TCK-044
Inductance	3.3 $\mu$ H $\pm$ 20% (at 1 kHz / 1 V)
Impedance (DCR)	60 m $\Omega$ max.
Rated Current	2 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions



### Impedance Curve

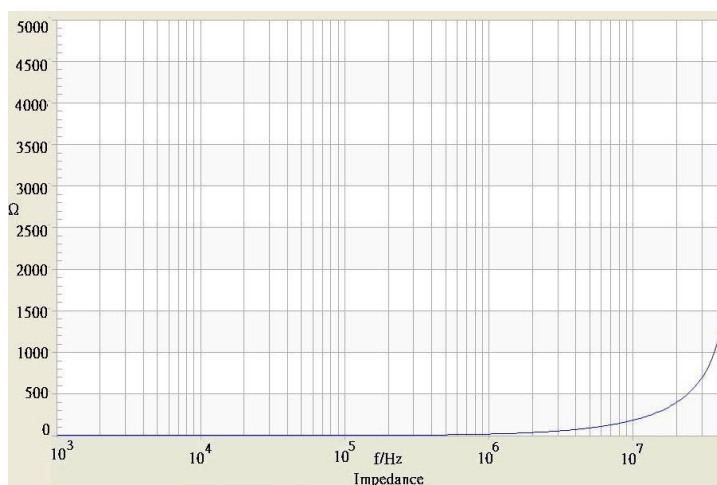

### Outline Dimensions

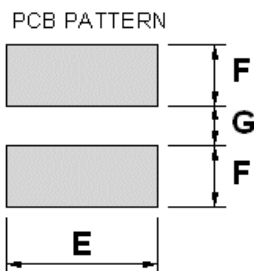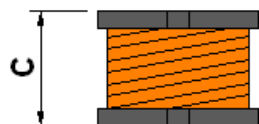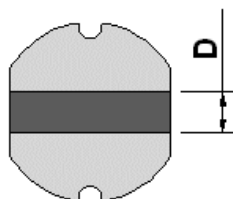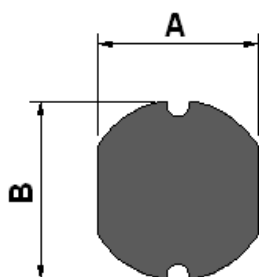

Dimensions [mm]	
A	5.2 $\pm$ 0.5
B	5.8 $\pm$ 0.5
C	5.2 max.
D	1.3 typ.
E	5.5
F	2.15
G	1.7

All specifications valid at +25°C, unless otherwise stated.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TRACO Power:](#)

[TCK-044](#)