




Order Code	TCK-077
Inductance	8.2 μ H $\pm$ 20% (at 1 kHz / 250 mV)
Impedance (DCR)	80 m Ω max.
Rated Current	1.5 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions

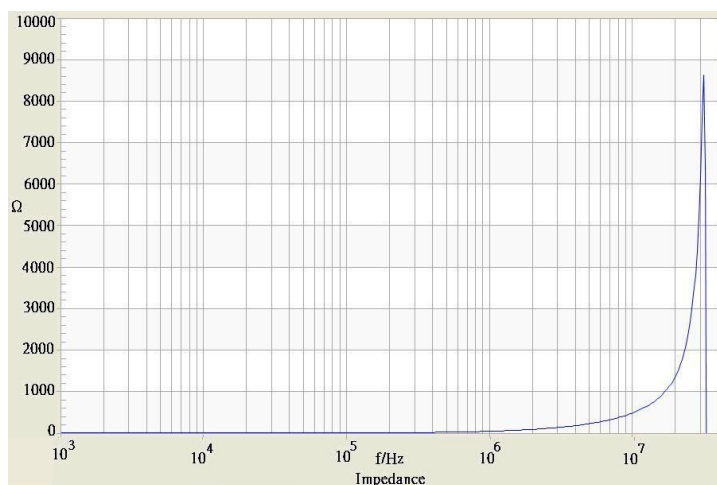


Impedance Curve




Outline Dimensions

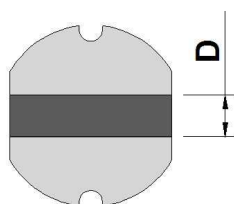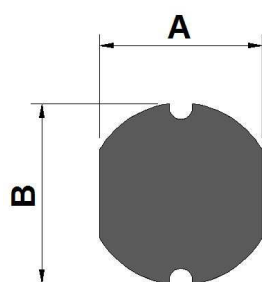

Dimensions [mm]	
A	5.2 $\pm$ 0.5
B	5.8 $\pm$ 0.5
C	4.5 $\pm$ 0.5
D	1.3 typ.
E	5.5
F	2.18
G	1.7

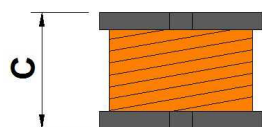

PCB PATTERN

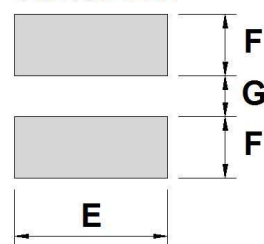

All specifications valid at +25°C, unless otherwise stated.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TRACO Power:](#)

[TCK-077](#)