



Common Mode Choke

TCK-090


Order Code	TCK-090
Inductance (each winding)	470 μ H \pm 25% (at 10 kHz / 100 mV)
Impedance (DCR)	60 m Ω max.
Rated Current	1 A max.
Rated Voltage	500 VDC max. (between windings)
Operating Temperature	-40°C to +105°C
RoHS Exemptions	No Exemptions

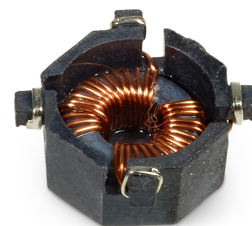

Impedance Curve

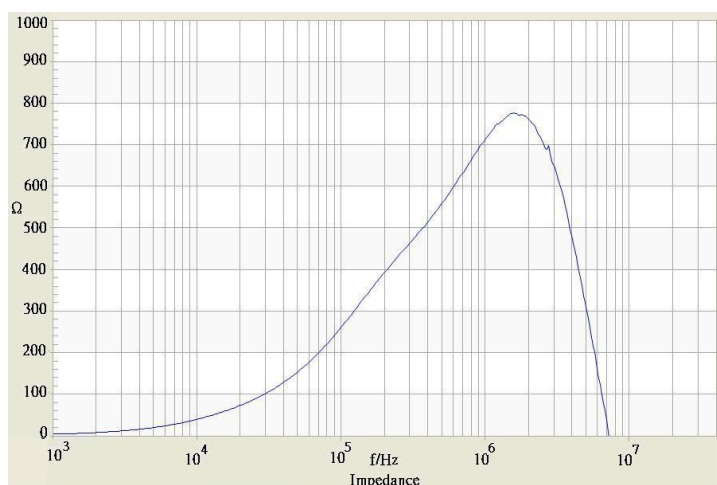

Outline Dimensions

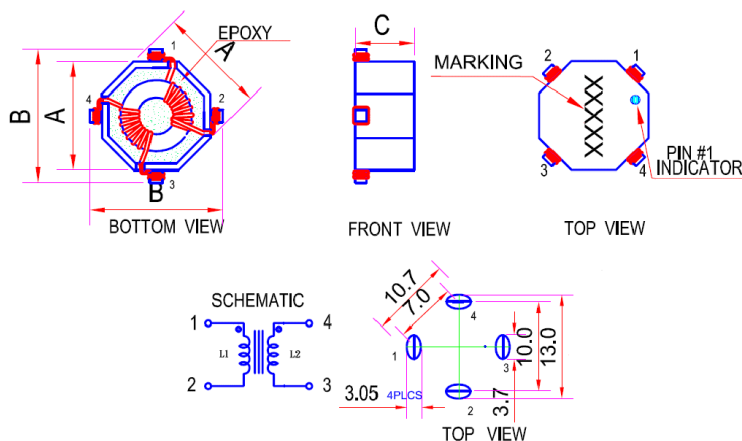

Dimensions [mm]	
A	9.2 max.
B	11.8 max.
C	5.0 max.
Marking	470UH

All specifications valid at +25°C, unless otherwise stated.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TRACO Power:](#)

[TCK-090](#)