



Order Code	TCK-097
Inductance	2.2 μ H \pm 20% (at 100 kHz / 250 mV)
Impedance (DCR)	12 m Ω max.
Rated Current	11 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions

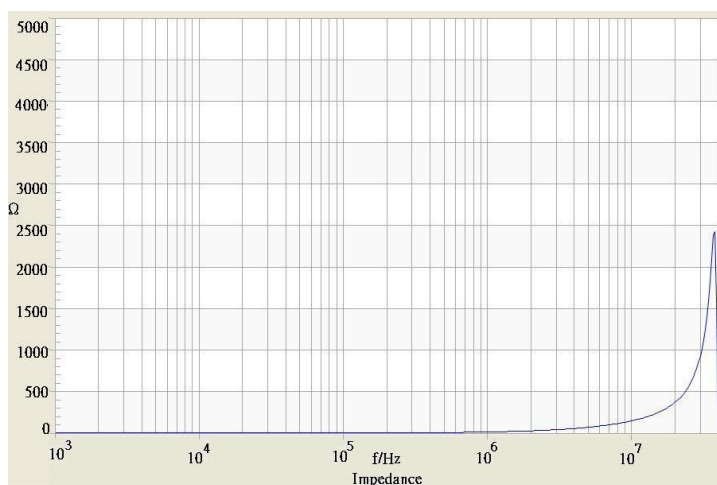


Impedance Curve



Outline Dimensions

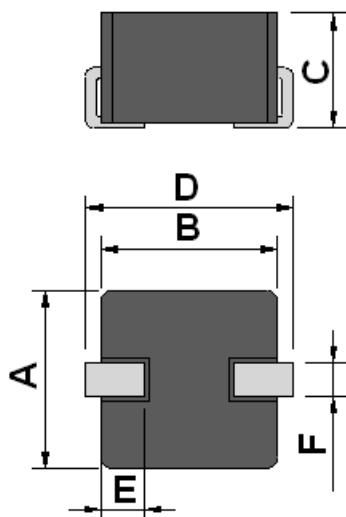

PCB PATTERN

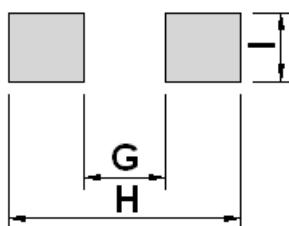

Dimensions [mm]

A	6.5 \pm 0.3
B	6.5 \pm 0.3
C	4.2 max.
D	7.6 max.
E	1.6 \pm 0.3
F	1.2 \pm 0.3
G	3.0
H	8.5
I	2.5

All specifications valid at +25°C, unless otherwise stated.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TRACO Power:](#)

[TCK-097](#)