






Order Code	TCK-098
Inductance	22 $\mu$ H $\pm$ 20% (at 1 kHz / 250 mV)
Impedance (DCR)	110 m $\Omega$ max.
Rated Current	1.5 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions



### Impedance Curve

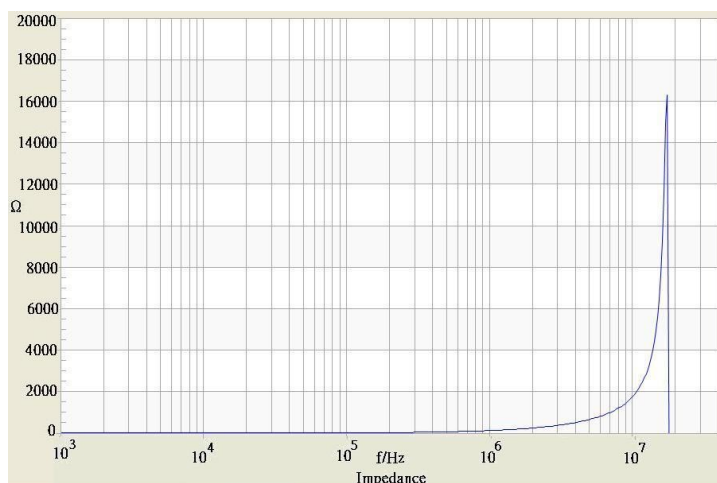

### Outline Dimensions

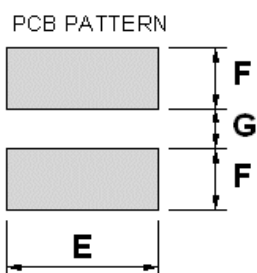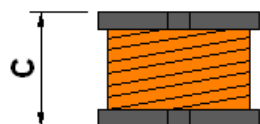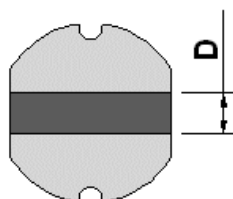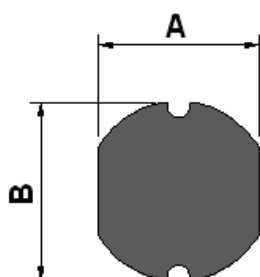

Dimensions [mm]	
A	7.0 $\pm$ 0.5
B	7.8 $\pm$ 0.5
C	5.0 $\pm$ 0.7
D	2.1 typ.
E	7.5
F	3
G	2

All specifications valid at +25°C, unless otherwise stated.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TRACO Power:](#)

[TCK-098](#)