




Order Code	TCK-103
Inductance (each winding)	285 $\mu$ H $\pm$ 35% (100 kHz / 100 mV)
Impedance (DCR)	6 m $\Omega$ max.
Rated Current	16 A max.
Rated Voltage	500 VDC max. (between windings)
Operating Temperature	-40°C to +105°C
RoHS Exemptions	No Exemptions

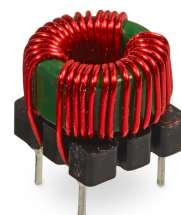

### Impedance Curve

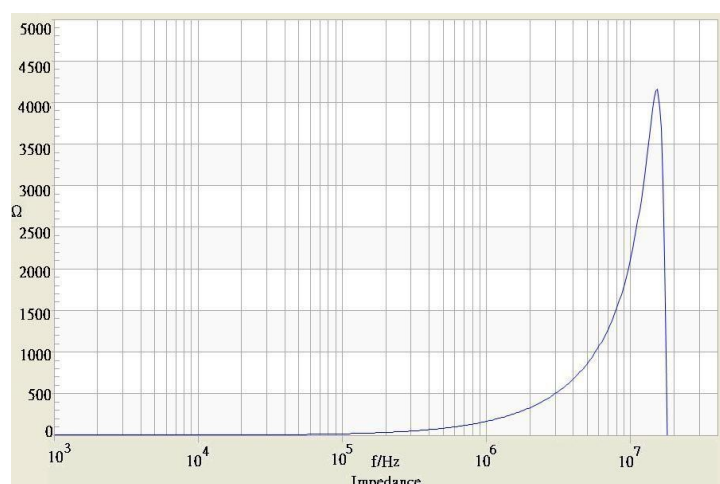

### Outline Dimensions

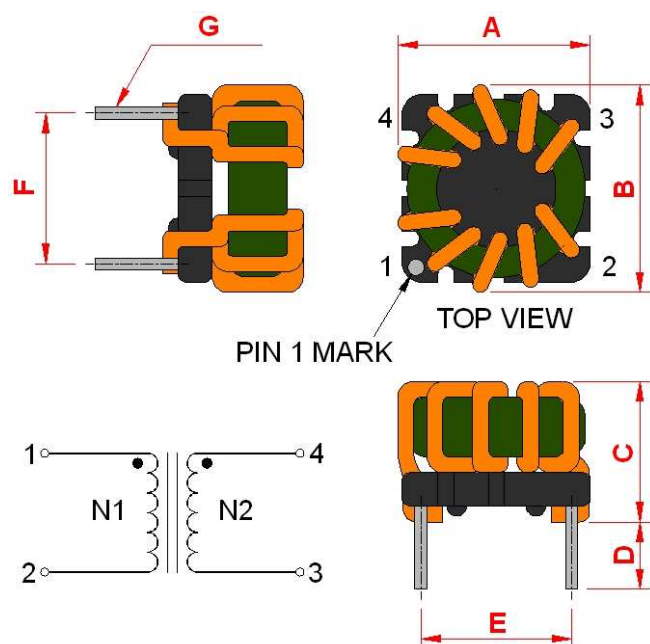

Dimensions [mm]	
A	16.0 max.
B	16.0 max.
C	15 max.
D	3.6 $\pm$ 0.3
E	10.0 $\pm$ 0.3
F	7.4 $\pm$ 0.3
G	$\varnothing$ 0.8

All specifications valid at +25°C, unless otherwise stated.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TRACO Power:](#)

[TCK-103](#)