






Order Code	TCK-111
Inductance	10 $\mu$ H $\pm$ 20% (at 1 kHz / 1 V)
Impedance (DCR)	182 m $\Omega$ max.
Rated Current	1.15 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions



### Impedance Curve

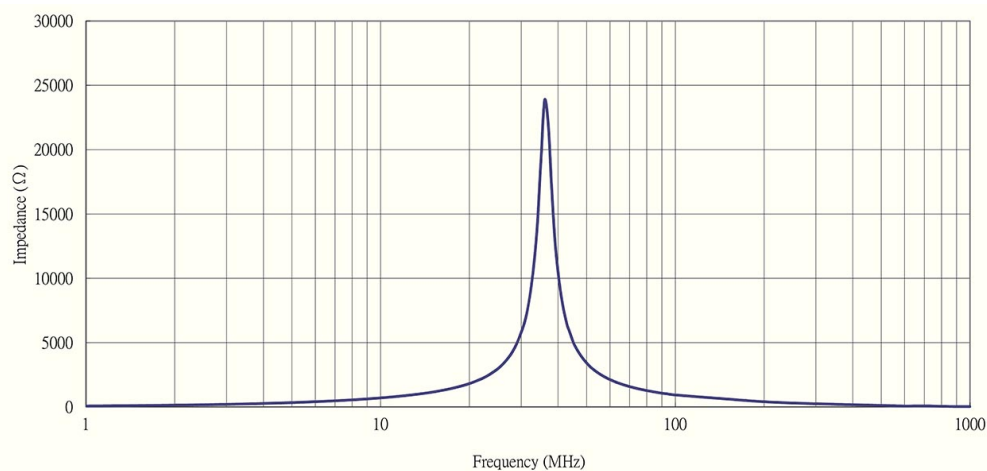

### Outline Dimensions

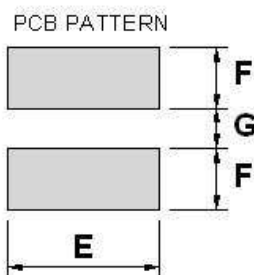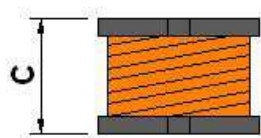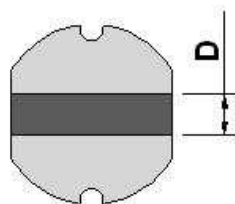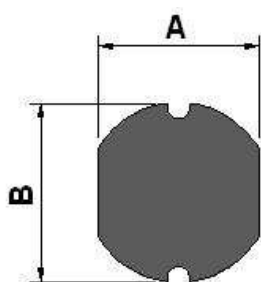

#### Dimensions [mm]

A	4.0 $\pm$ 0.5
B	4.5 $\pm$ 0.5
C	3.2 $\pm$ 0.5
D	1.2 typ.
E	4.5
F	1.75
G	1.5

All specifications valid at +25°C, unless otherwise stated.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TRACO Power:](#)

[TCK-111](#)