



Common Mode Choke

TCK-118


Order Code	TCK-118
Inductance (each winding)	175 μ H \pm 25% (at 10 kHz / 50 mV)
Impedance (DCR)	34 m Ω max.
Rated Current	1.76 A max.
Rated Voltage	500 VDC max. (between windings)
Operating Temperature	-40°C to +105°C
RoHS Exemptions	No Exemptions

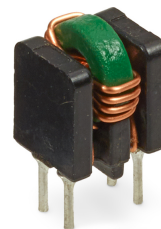

Impedance Curve

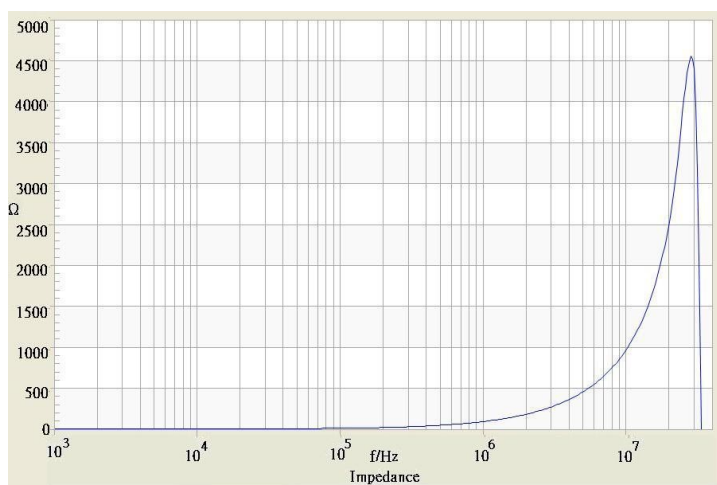

Outline Dimensions

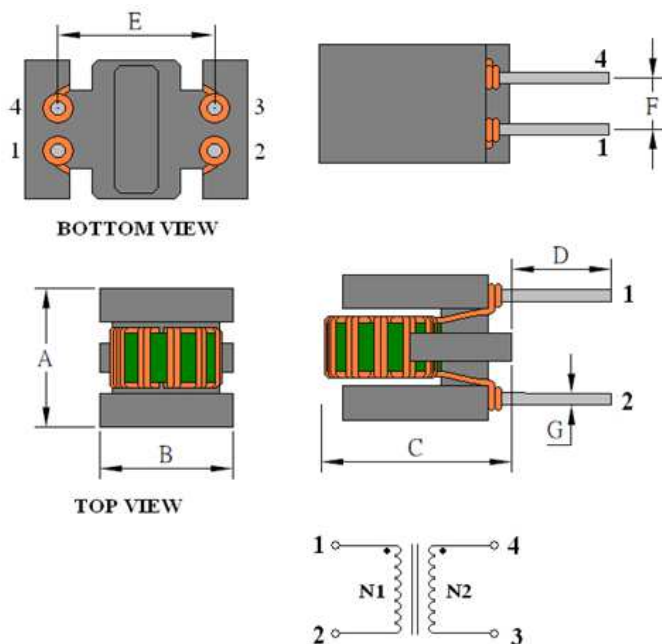

Dimensions [mm]	
A	7.5 max.
B	8.5 max.
C	10.5 max.
D	3.5 \pm 1.0
E	5.08 \pm 0.5
F	2.54 \pm 0.3
G	\varnothing 0.6 \pm 0.1

All specifications valid at +25°C, unless otherwise stated.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TRACO Power:](#)

[TCK-118](#)