






| | |
|-----------------------|--|
| Order Code | TCK-130 |
| Inductance | 22 μ H \pm 15% (at 100 kHz / 250 mV) |
| Impedance (DCR) | 55 m Ω max. |
| Rated Current | 0.58 A max. |
| Operating Temperature | -40°C to +125°C |
| RoHS Exemptions | No Exemptions |

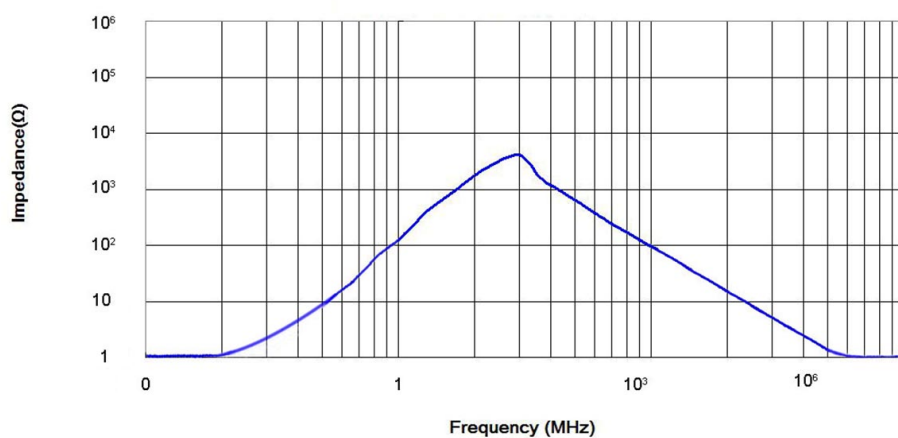

Impedance Curve



Outline Dimensions

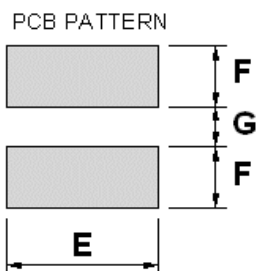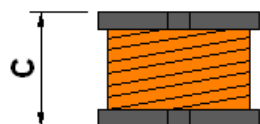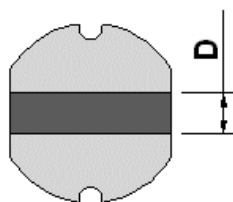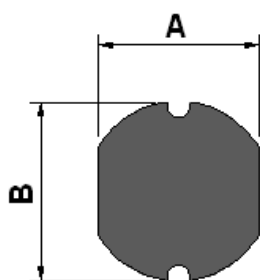

| Dimensions [mm] | |
|-----------------|---------------|
| A | 3.0 \pm 0.5 |
| B | 3.5 \pm 0.5 |
| C | 2.0 \pm 0.5 |
| D | 1.2 typ. |
| E | 3.6 |
| F | 1.7 |
| G | 0.8 |

All specifications valid at +25°C, unless otherwise stated.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TRACO Power:](#)

[TCK-130](#)