



Order Code	TCK-149
Inductance	22 $\mu$ H $\pm$ 20% (at 100 kHz / 1 V)
Impedance (DCR)	240 m $\Omega$ max.
Rated Current	1.1 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions




### Impedance Curve

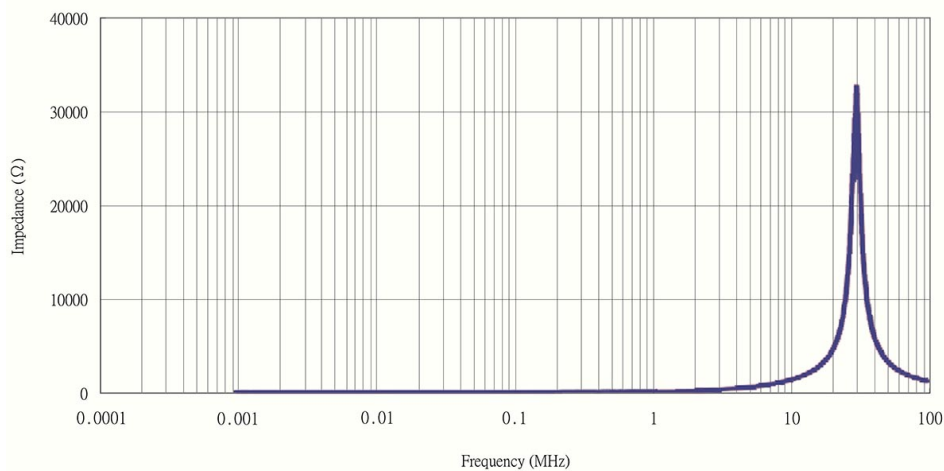

### Outline Dimensions

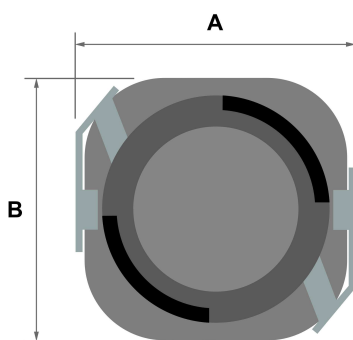

Dimensions [mm]	
A	5.3 $\pm$ 0.4
B	5.0 $\pm$ 0.4
C	2.7 $\pm$ 0.5
D	2
E	2
F	2

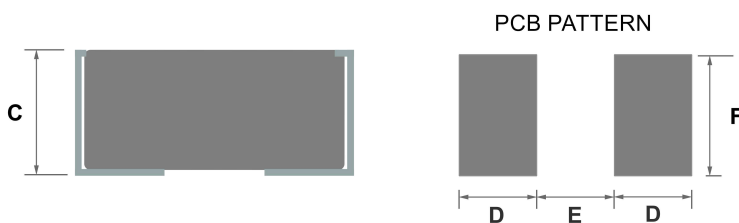

All specifications valid at +25°C, unless otherwise stated.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TRACO Power:](#)

[TCK-149](#)