



Order Code	TCK-161
Inductance	150 μ H \pm 20% (at 100 kHz / 1 V)
Impedance (DCR)	1548 m Ω max.
Rated Current	0.32 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions




Impedance Curve

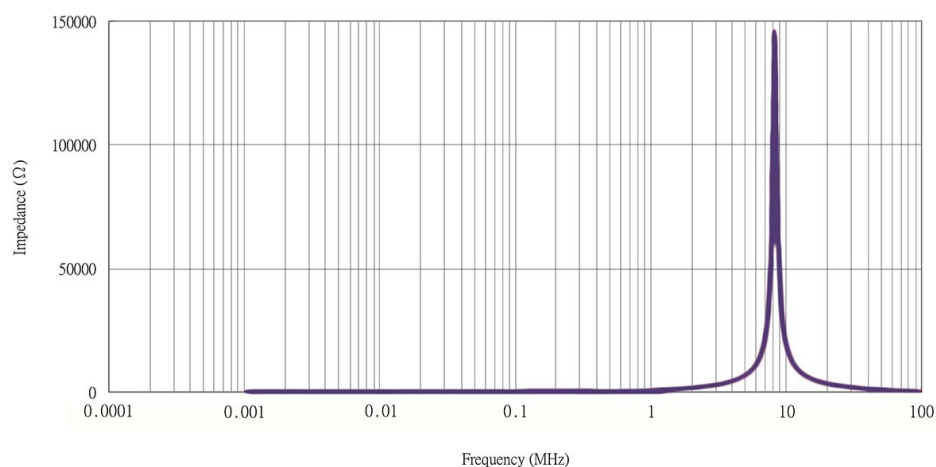

Outline Dimensions

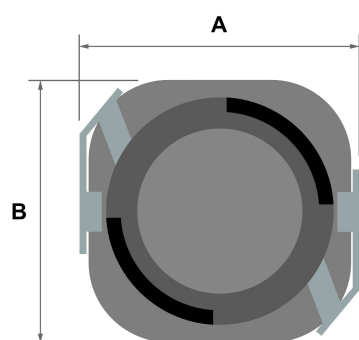

Dimensions [mm]	
A	5.3 \pm 0.4
B	5.0 \pm 0.4
C	2.7 \pm 0.5
D	2
E	2
F	2

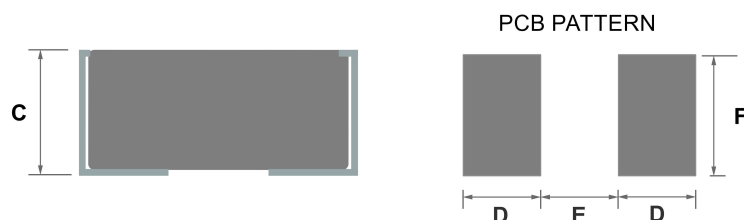

All specifications valid at +25°C, unless otherwise stated.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TRACO Power:](#)

[TCK-161](#)