




Order Code	TCK-182
Inductance	100 µH ±20% (at 100 kHz / 1 V)
Impedance (DCR)	589 mΩ max.
Rated Current	0.8 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions



Impedance Curve

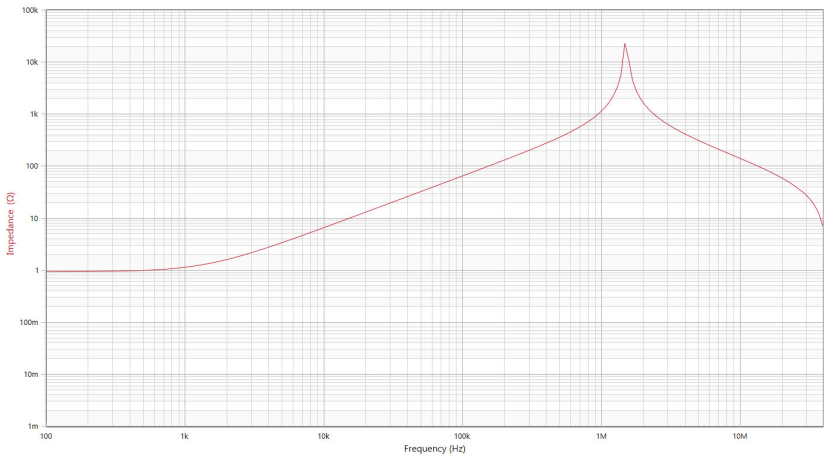

Outline Dimensions

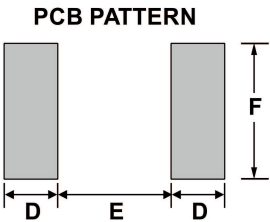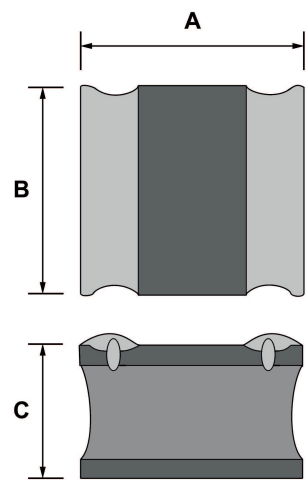

Dimensions [mm]	
A	4.9 ±0.4
B	4.9 ±0.4
C	4.2 max.
D	1.5
E	2.1
F	4.0

All specifications valid at +25°C, unless otherwise stated.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TRACO Power:](#)

[TCK-182](#)