



Order Code	TCK-112
Inductance	12 μ H \pm 20% (at 100 kHz / 250 mV)
Impedance (DCR)	53 m Ω max.
Rated Current	4 A max.
Operating Temperature	-40°C to +125°C
RoHS Exemptions	No Exemptions
Overview Link	www.tracopower.com/overview/tck-112

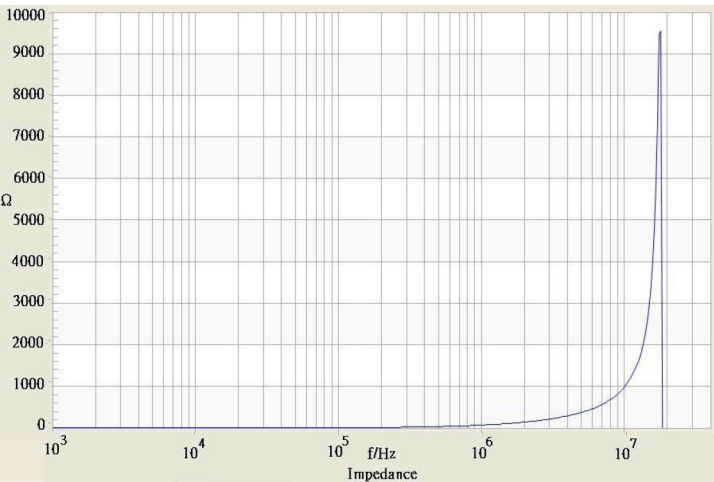

Impedance Curve



Outline Dimensions

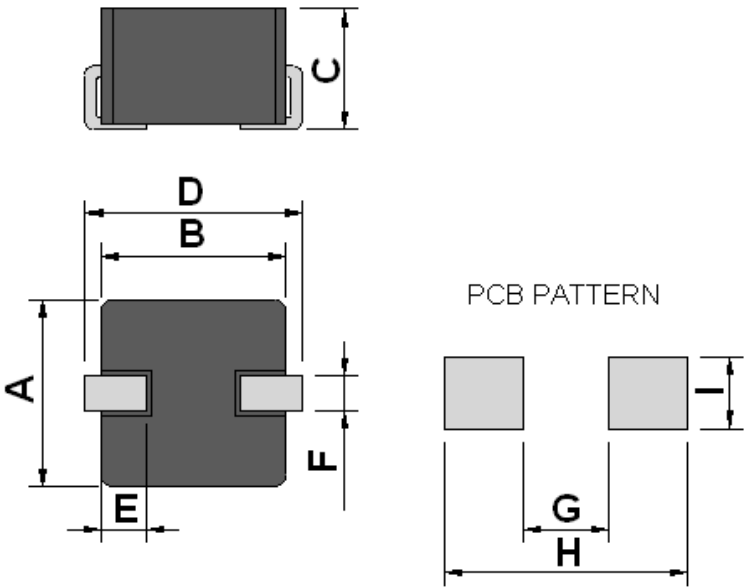

Dimensions [mm]	
A	6.5 \pm 0.2
B	6.5 \pm 0.2
C	3.85 \pm 0.15
D	7.6 max.
E	1.5 \pm 0.3
F	1.2 \pm 0.3
G	3.0
H	8.5
I	2.5

All specifications valid at +25°C, unless otherwise stated.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[TRACO Power:](#)

[TCK-112](#)