
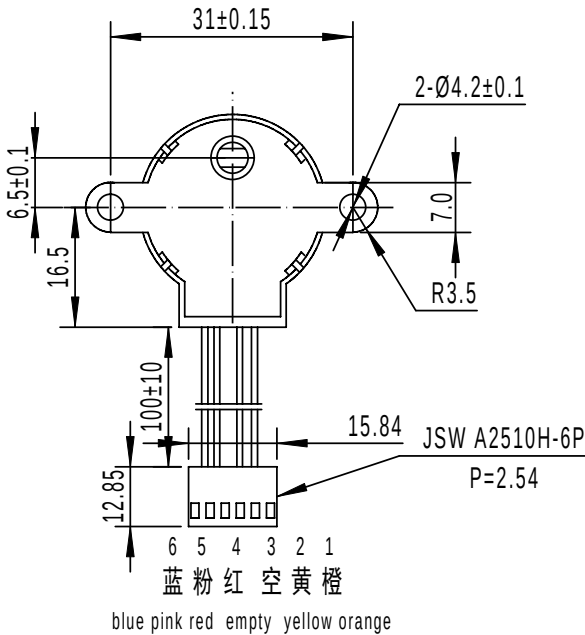



ITEM	Specification Condition
N0. of Phase	4
Step Angle	5.625°/25
Operating Voltage	DC 5V (Terminal Voltage)
Excitation	1-2 Phase Excitation.
Winding Resistance	120±10% Ω At 25℃
Pull-In Torque	200g.cm min ,100pps DC5V
Stepping Accuracy	5.625°±7%
Pull In Rate	600pps min
Moderating Ratio	1/25

TS-24BYJ48A-25 STEPPING MOTOR

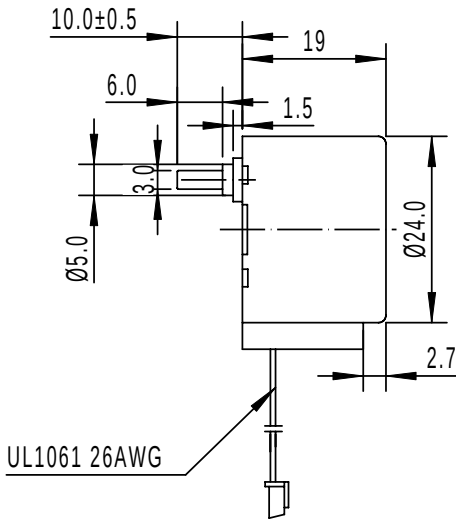

lable

TS-24BYJ48A-25
5VDC 120 Ω 1:25

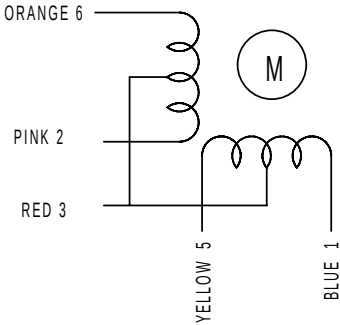

TITLE: TS-24BYJ48A-25	Customer No:	Drafted By: kevin wang		
		Checked By:		
Dwg. NO:JL-120-25A	Date: 2015.04.11	Approved By:		
TT MOTOR (HK) INDUSTRIL CO.,LTD	Scale: 1:1	Units: mm	EDITION No: A	
		Angular: =1° Decimal: X.XX ±0.05		
		X.X ±0.2		
		X ±0.3		

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Digilent:

290-028