

**10 cm (4") 2-Wege-Koaxiallautsprecher** mit Polypropylenmembran und Polycarbonat-Hochtöner. Integrierte Frequenzweiche (Kondensator) für den Hochtöner. Ausgewogener Klang. Unproblematische Montage in Fahrzeugen mit 10-cm-Einbauöffnungen. Mit Montagering und Gitter Einbau auf Türverkleidungen und Heckablagen möglich. Paarweise verpackt.

**Anwendungsmöglichkeiten:** Fahrzeuge, Reisemobile

**Zubehör:** Inklusive Montagematerial und Gitter.


**10 cm (4") 2-way coaxial loudspeakers** with 10 cm polypropylene cone and polycarbonate dome tweeter. Integrated crossover (capacitor) for the tweeter. Very balanced sound. Straightforward installation in vehicles with 10 cm cutouts. Door and rear tray installation possible using mounting ring and grille. Packed in pairs.

**Typical applications:** Vehicles, Mobile homes


**Accessories:** Mounting accessories and grilles are included.

**DX 10**

**Art. No. 4610 – 4 Ω**

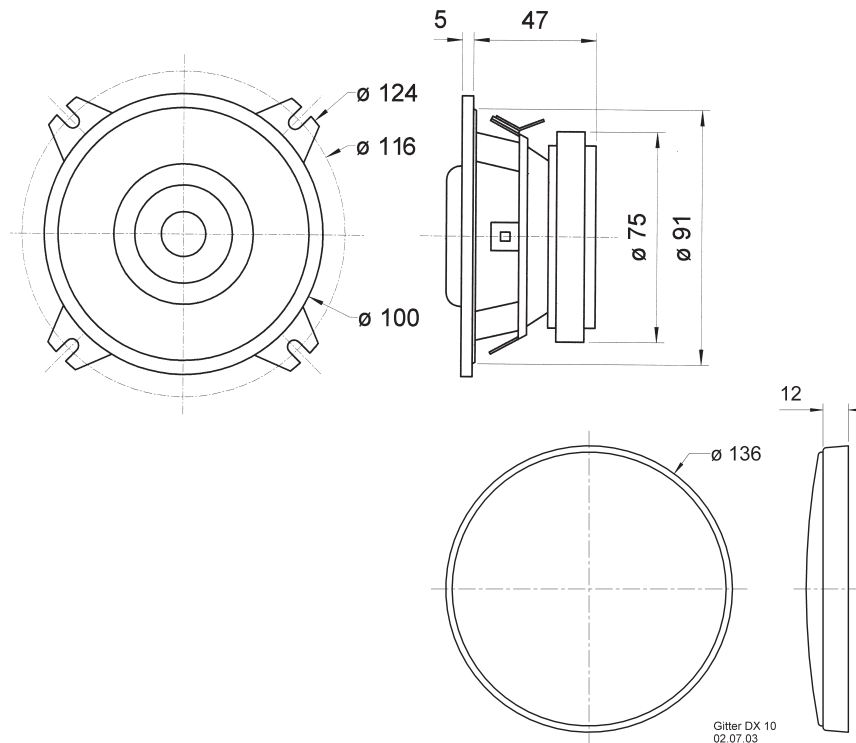


DX 10 - 4 Ohm

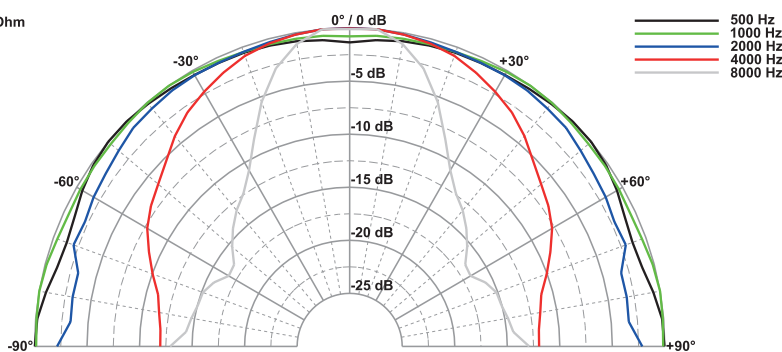

#### Technische Daten / Technical Data

|                                                             |                   |
|-------------------------------------------------------------|-------------------|
| Nennbelastbarkeit<br>Rated power                            | 50 W              |
| Musikbelastbarkeit<br>Maximum power                         | 70 W              |
| Impedanz<br>Impedance                                       | 4 Ω               |
| Übertragungsbereich (–10 dB)<br>Frequency response (–10 dB) | 80–20000 Hz       |
| Mittlerer Schalldruckpegel<br>Mean sound pressure level     | 88 dB (1 W/1 m)   |
| Grenzauslenkung $x_{mech}$<br>Excursion limit $x_{mech}$    | ± 3 mm            |
| Resonanzfrequenz<br>Resonant frequency                      | 110 Hz            |
| Obere Polplattenhöhe<br>Height of front pole-plate          | 4 mm              |
| Schwingspulendurchmesser<br>Voice coil diameter             | 25 mm Ø / 14 mm Ø |
| Wickelhöhe<br>Height of winding                             | 6 mm              |
| Schallwandöffnung<br>Cut-out diameter                       | 91 mm Ø           |
| Gewicht netto<br>Net weight                                 | 0,64 kg           |

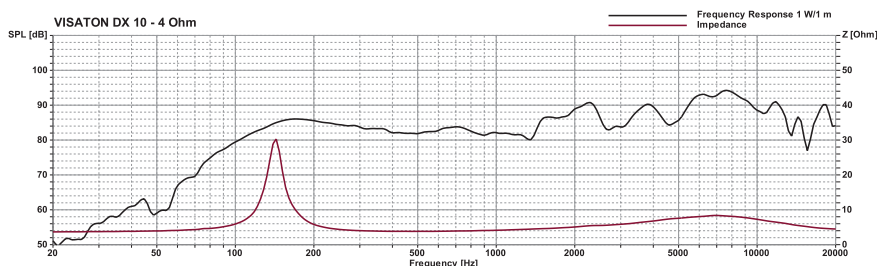

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Visaton:

[DX 10 - 4 Ohm](#)