

SC 8 N

Art. No. 8018 – 8 Ω



Technische Daten / Technical Data

Nennbelastbarkeit	
Rated power	30 W
Impedanz	
Impedance	8 Ω
Übertragungsbereich (–10 dB)	
Frequency response (–10 dB)	70–20000 Hz
Mittlerer Schalldruckpegel	
Mean sound pressure level	81 dB (1 W/1 m)
Grenzauslenkung x_{mech}	
Excursion limit x_{mech}	± 3 mm
Resonanzfrequenz	
Resonant frequency	110 Hz
Obere Polplattenhöhe	
Height of front pole-plate	3 mm
Schwingspulendurchmesser	
Voice coil diameter	20 mm Ø
Wickelhöhe	
Height of winding	4 mm
Schallwandöffnung	
Cut-out diameter	73 mm Ø
Anschluss	
Terminal	4,8 x 0,8 mm (+)/2,8 x 0,8 mm (–)
Gewicht netto	
Net weight	0,28 kg


Weitere Daten Seiten / for further data see pages 385–386

Magnetisch abgeschirmter 8 cm (3,3“) Breitbandlautsprecher mit Cellulose-Membran und inverser Gummisicke. Sehr ausgeglichener Frequenzgang. Kunststoff: ABS V0 (UL 94: V-0)

Anwendungsmöglichkeiten: Multi-Media-Boxen, Video-Monitore, Fernsehgeräte, Computerterminals



Magnetically shielded 8 cm (3.3“) fullrange driver with cellulose cone and rubber inverted surround. Very balanced frequency response. Plastic: ABS V0 (UL 94: V-0)

Typical applications: Multimedia systems, Video monitoring screens, TVs, Computer terminals

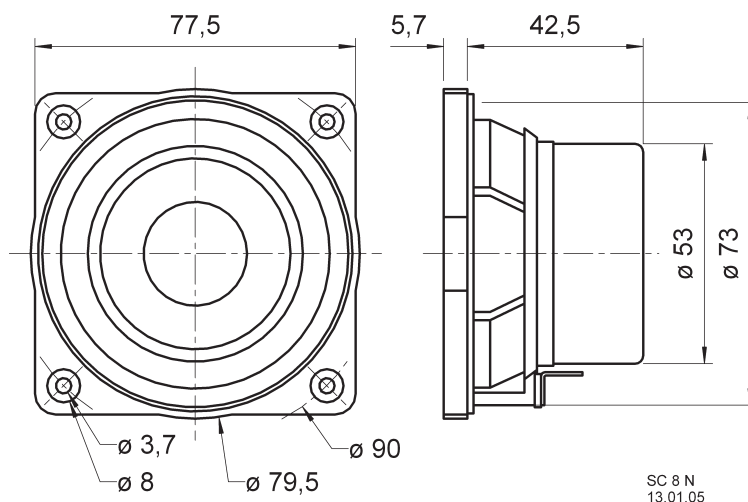

SC 8 N
13.01.05

SC 8 N - 8 Ohm

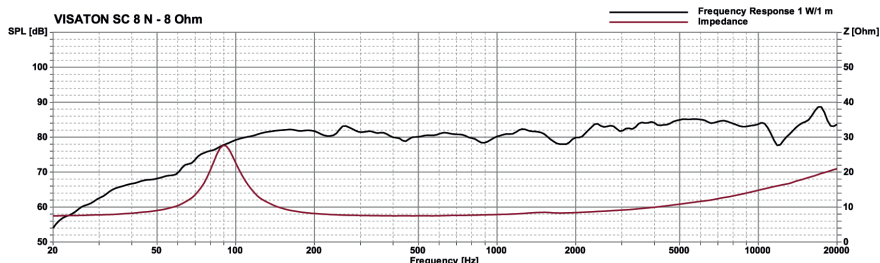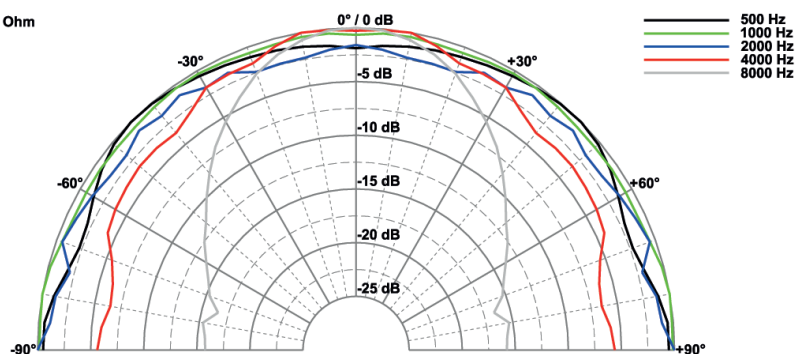

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Visaton:](#)

[8018](#)