

WL 13 P – Art. No. 50321

ohne Lautstärkeregler / without volume control

WL 13 PR – Art. No. 50323

mit Lautstärkeregler / with volume control



Technische Daten / Technical Data


Trafoanpassung Transformer matching	6/3/1,5 W
Schalldruckpegel Sound pressure level	94 dB (1 W/1 m) @ 5312 Hz
Abstrahlwinkel (-6 dB) Opening angle (-6 dB)	74° hor. / 67° vert. / 4000 Hz
Übertragungsbereich (-10 dB) Frequency response (-10 dB)	90–16000 Hz
Mittlerer Schalldruckpegel Mean sound pressure level	88 dB (1 W/1 m)
Max. Schalldruckpegel Max. sound pressure level	96 dB (6 W/1 m)
Farbe Colour	ähnlich / similar RAL 9010
Anschluss Terminal	Federklemmen Spring terminals
Gewicht netto Net weight	1,15 kg

Wandlautsprecher mit weißem Kunststoffgehäuse und Aluminium-Lochblech-Abdeckung. Bestückt mit einem hochwertigen Breitbandlautsprecher. Gute Musikwiedergabe und klare Sprachverständlichkeit. Anschluss an das 100-V-Netz und Pegelanpassung durch Druckfederklemme. Wahlweise mit Lautstärkeregler.

- Kunststoff: ABS V0 (UL 94: V-0)


Wall-mounted speaker with a white plastic cabinet and metal grille. Fitted with a high-quality full range driver. Removable rear panel for easy fitting to the wall using two screws. Good music reproduction and clear speech reproduction properties. Connection to 100 volt network and level trimming by means of spring terminal. Volume control optional.

- Plastic: ABS V0 (UL 94: V-0)


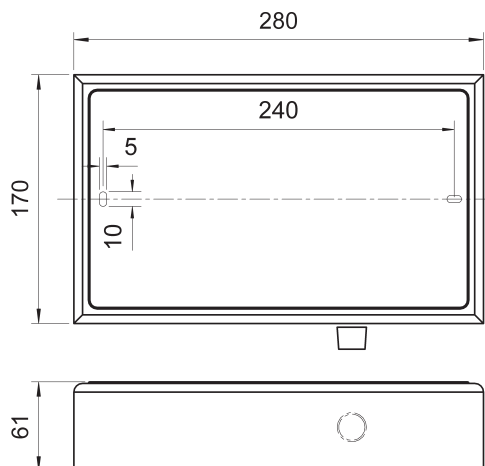


WL 13 P/PR/PRP
20.03.2006

WL 13 P - 100 V (A')

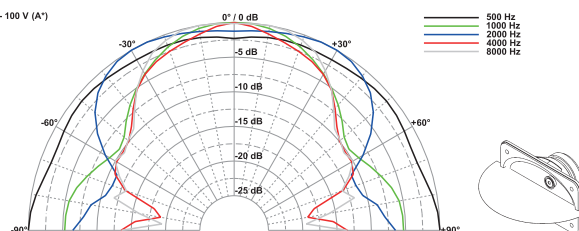

WL 13 P - 100 V (B')

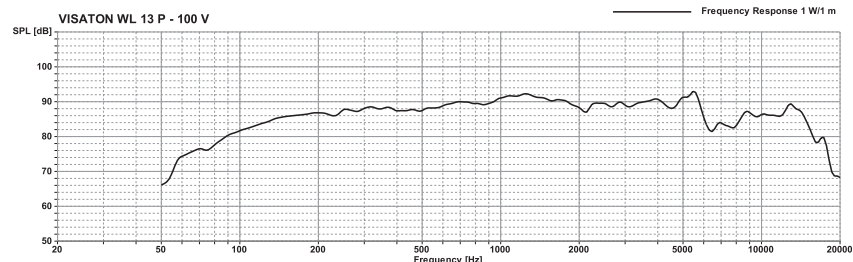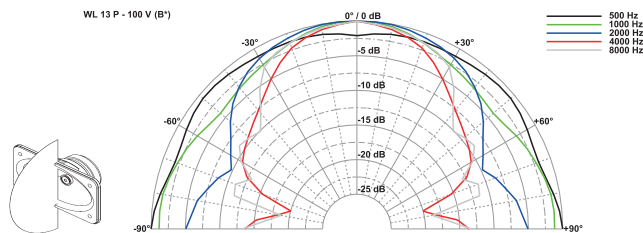

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Visaton:](#)

[50323](#)