


Stacking Banana Plug Test Lead, PVC

4mm Stacking, Retractable Sleeve, Straight, Banana Plug to Stacking, Retractable...

Description

Added safety and protection when standard banana jack connections are encountered. With PVC jacketed wire, 0.75 mm²(18 AWG). Clear covering sleeve retracts as you plug into the jack. Banana plug includes a Grey plastic insulation tip for added protection.

- Materials: Body: Polyamide; Contact: Brass, Nickel Plt.
- Banana Contact: BeCu, Nickel Plt.
- Meets IEC 61010-031 safety specifications

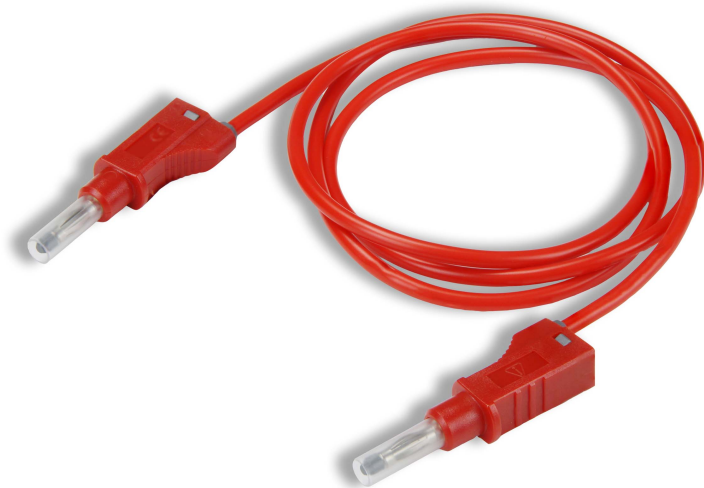

Technical data subject to change.

© Cal Test Electronics 2018.

caltestelectronics.com

All specifications apply to the unit after a temperature stabilization time of 20 minutes over an ambient temperature range of 25°C ± 5°C.

Specifications

IEC Rating	600 V CAT II
Current Max	12 A
Resistance Max	10 milliohms
Jacket Material	PVC
Conductor Area	0.75 mm ²
Wire Gauge	18 AWG
Stranding (# x dia.)	195 x 0.07 mm
Jacket OD	3.7 mm (0.146")
Temperature (degrees)	-20 to +80C
RoHS (2011/65/EU)	Compliant

Specifications are subject to change without notice. To ensure the most current version of this manual, please download the current version from our website: caltestelectronics.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Cal Test Electronics:

[CT2147-10-0](#) [CT2147-100-4](#) [CT2147-100-5](#) [CT2147-100-6](#) [CT2147-100-9](#) [CT2147-10-2](#) [CT2147-50-6](#) [CT2147-50-9](#) [CT2147-25-4](#) [CT2147-25-5](#) [CT2147-25-6](#) [CT2147-25-9](#) [CT2147-50-4](#) [CT2147-50-5](#) [CT2147-200-4](#) [CT2147-200-5](#) [CT2147-200-6](#) [CT2147-200-9](#) [CT2147-25-0](#) [CT2147-25-2](#) [CT2147-150-4](#) [CT2147-150-5](#) [CT2147-150-6](#) [CT2147-150-9](#) [CT2147-200-0](#) [CT2147-200-2](#) [CT2147-10-4](#) [CT2147-10-5](#) [CT2147-10-6](#) [CT2147-10-9](#) [CT2147-150-0](#) [CT2147-150-2](#)