

CT2900A

2mm Digital Multimeter Probe


Datasheet

UL listed probe set with 2 mm (0080") diameter probe...

Description

UL listed DMM probe set with 2 mm (0.080") diameter probe tip.
Connector is a right-angle sheathed 4 mm banana plug. Set includes alligator clip pair featuring gold plated pin tip sockets. They mate easily onto the probe tips.

- Materials: Body: PVC/Nylon; Contact: Brass, Nickel Plt.
- Banana Contact: Phosphor Bronze, Nickel Plt.
- Alligator Clips: Steel, Nickel Plt.

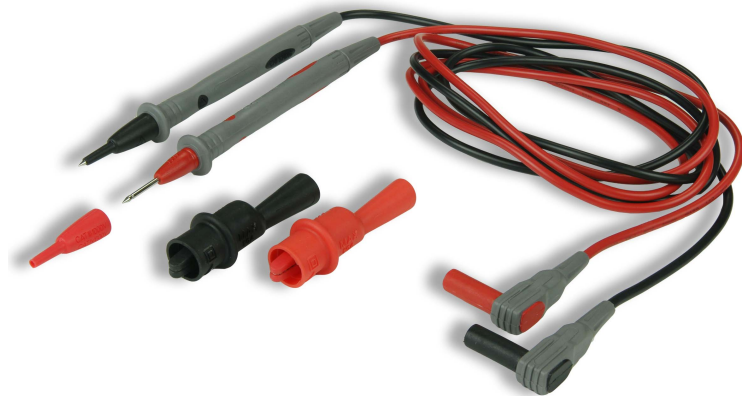

Technical data subject to change.

© Cal Test Electronics 2018.

caltestelectronics.com



All specifications apply to the unit after a temperature stabilization time of 20 minutes over an ambient temperature range of 25°C ± 5°C.

Specifications

IEC Rating	1,000 V CAT III
Current Max	12 A
Resistance Max	30 mohm
Jacket Material	PVC
Conductor Area, square millimeters	0.75
Wire Gauge, AWG	18
Stranding, # x mm	195 x 0.07
OD, mm (in)	3.7mm (0.146")
Temperature (degrees)	-20 to +80 degC
RoHS (2011/65/EU)	Pending

Specifications are subject to change without notice. To ensure the most current version of this manual, please download the current version from our website: caltestelectronics.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Cal Test Electronics:](#)

[CT2900A](#)