

CT3160


Double Banana Plug

Molded 4 mm double banana plug or MDP banana plug...

Description

Molded 4 mm double banana plug or MDP banana plug.
Do-It-Yourself easy to assembly without solder dual banana plug.

- Materials: Body: ABS; Plug: Brass, Nickel Plt; Contact: BeCu, Nickel Plt.
- Cable diameters to 5.5 mm (0.21")
- Wire attachment to 18 - 22 AWG

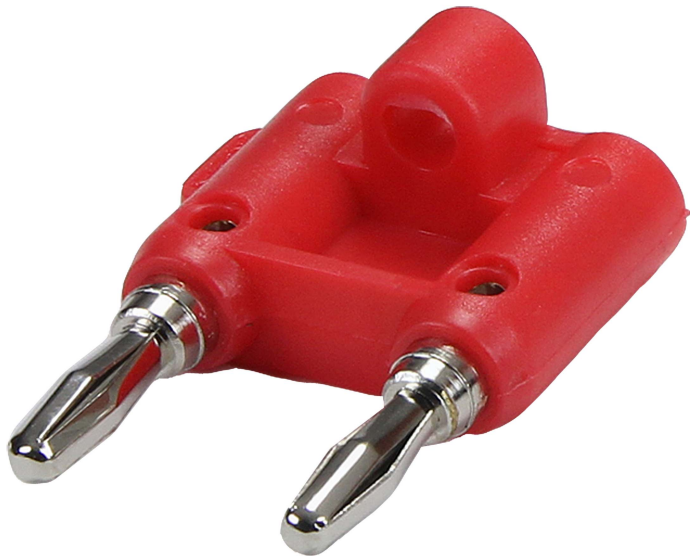

Technical data subject to change.

© Cal Test Electronics 2018.

caltestelectronics.com

Datasheet

All specifications apply to the unit after a temperature stabilization time of 20 minutes over an ambient temperature range of 25°C ± 5°C.

Specifications

IEC Rating	33 Vac / 70 Vdc
Voltage Max	5,000 Vdc
Current Max	15 A
Resistance Max	5 mohm
Temperature (degrees)	-20 to +80 degC
RoHS (2011/65/EU)	Compliant

Specifications are subject to change without notice. To ensure the most current version of this manual, please download the current version from our website: caltestelectronics.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Cal Test Electronics:](#)

[CT3160-0](#)