

CT3802

Banana Plug Test Lead


Datasheet

4mm Straight Sheath Banana Plug to Insulated Alligator Clip Test Lead,...

Description

4mm Straight Sheath Banana Plug to Insulated Alligator Clip Test Lead. Highly flexible silicone jacketed test lead wire.

- Banana Contact: BeCu, Nickel Plt.
- Alligator Clip: Steel, Nickel Plt.
- Jaws open to 0.31" (7.9 mm)
- Available in 2 standard lengths
- Available in 2 colors

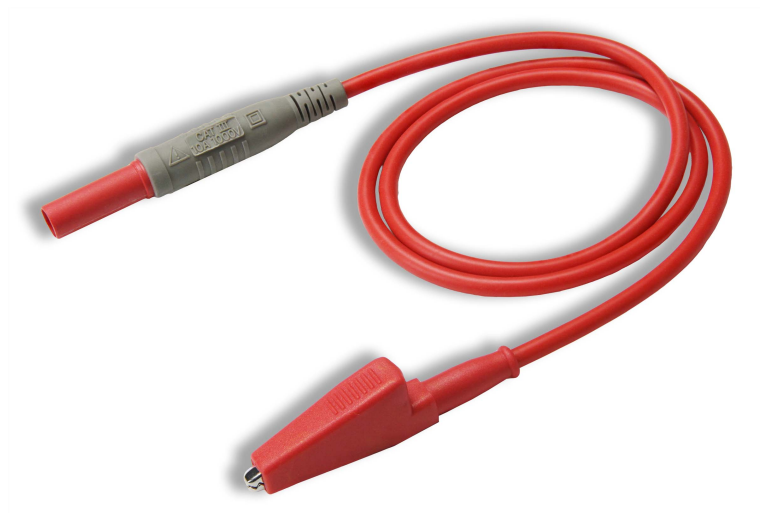

Technical data subject to change.

© Cal Test Electronics 2018.

caltestelectronics.com



All specifications apply to the unit after a temperature stabilization time of 20 minutes over an ambient temperature range of 25°C ± 5°C.

Specifications

UL Rating	300 V CAT II
Current, Max	10 A
Jacket Material	Silicone
Conductor Area	0.87 mm ²
Wire Gauge, AWG	18 AWG
Stranding (# x dia.)	168 x 0.07 mm
Jacket OD	3.7 mm (0.146")
Temperature (degrees)	-20 to +80C
RoHS (2011/65/EU)	Compliant

Specifications are subject to change without notice. To ensure the most current version of this manual, please download the current version from our website: caltestelectronics.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Cal Test Electronics:](#)

[CT3802-30-2](#) [CT3802-60-0](#) [CT3802-60-2](#) [CT3802-30-0](#)