

Medium Insulated Alligator Clip Adapter With 2mm Pin Jack, B/R Pair

CT4439

Features:

- IEC 61010-031 rated to 1,000 V CAT III / 600 V CAT IV
- 10 A Max
- Jaw opens to 8.5 mm
- Three-incisor mouth to ensure grip on screw heads.
- Connects to 2 mm pin tips or standard DMM probes
- CE listed
- RoHS 2 Compliant




Description:

The CT4439 is rated to 1,000 V CAT III / 600 V CAT IV^a and 10 A max.

The clips come with a 2 mm pin jack for connections to 2 mm pin tips or standard DMM probes. They can accommodate conductors up to 7 mm in diameter. Once in place, the spring loaded, three-incisor mouth will hold securely to screw heads or flat headed objects.

a. Must be used in conjunction with other similarly rated products.

Mechanical Drawing: Dimensions in mm, not to scale

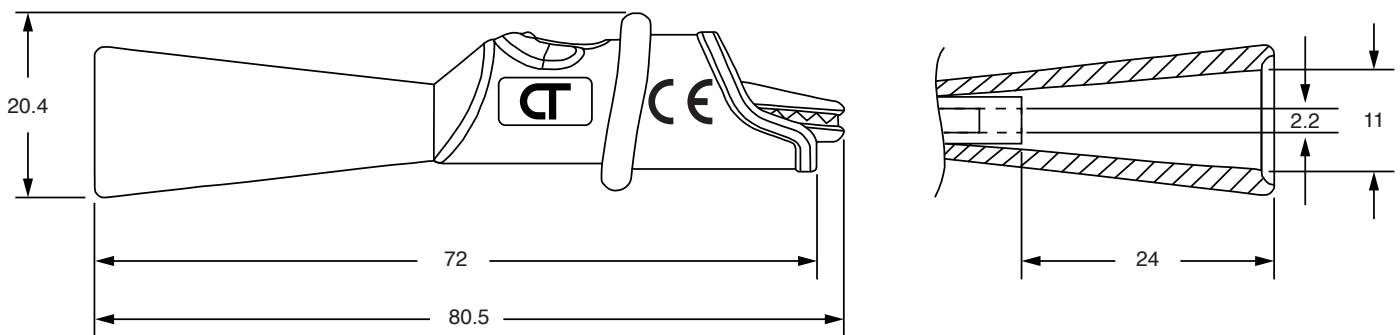

Specifications and appearance subject to change without notice
D443900 110320

1 - www.caltestelectronics.com

Order Information:

CT4439

Medium Alligator Clip Adapter With 2mm Pin Jack, B/R Pair

Contact Info:

Toll Free: 800-572-1028 (US Only)

Phone: 714-221-9330

Fax: 714-921-9849

22820 Savi Ranch Parkway

Yorba Linda, CA 92887-4610 USA

www.caltestelectronics.com

Assembly Image: *(Probe sold separately)*



Copyright © 2020, Cal Test Electronics, Inc. All rights reserved. Information in this publication supersedes that in all previously published material. Trade names referenced are the service marks, trademarks or registered trademarks of their respective companies.

Specifications and appearance subject to change without notice
D443900 110320

2 - www.caltestelectronics.com

Cal Test
ELECTRONICS

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Cal Test Electronics:](#)

[CT4439](#)