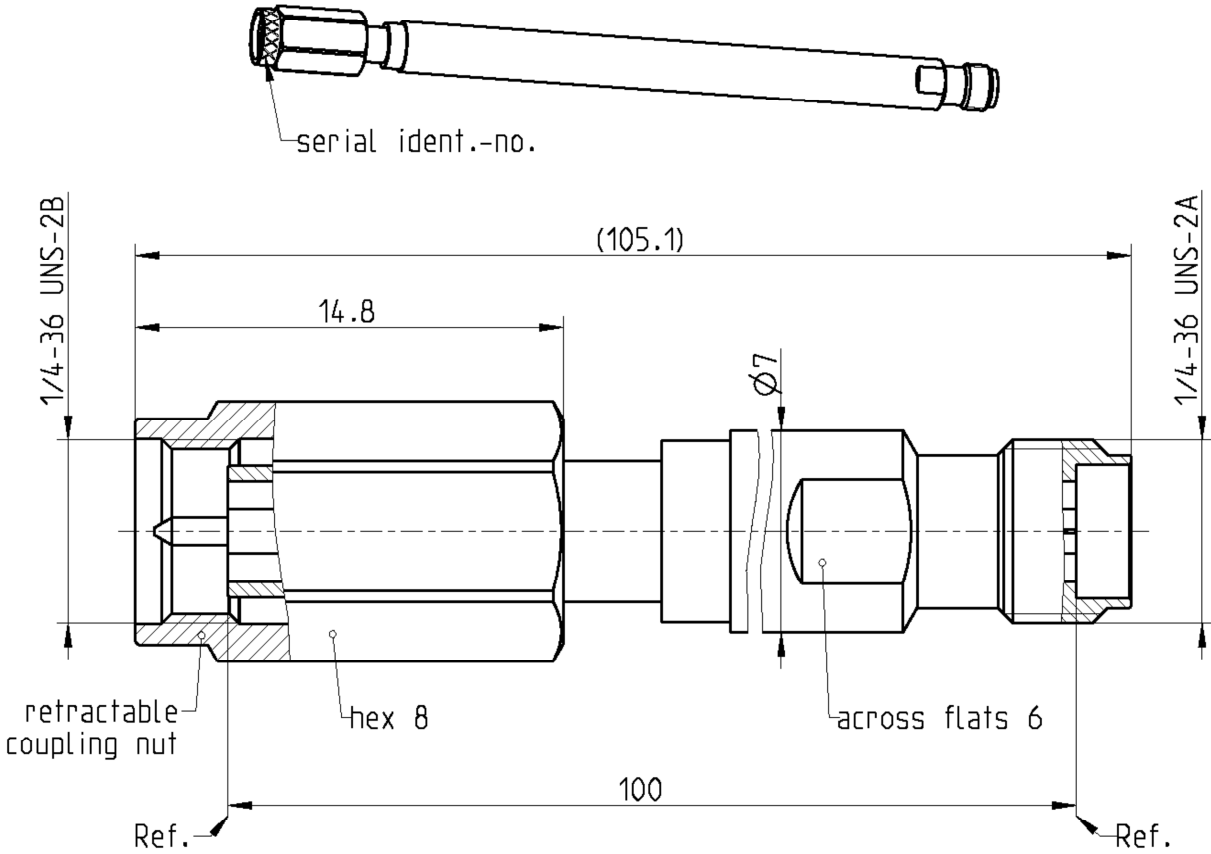


Technical Data Sheet		Rosenberger
RPC-3.50	Mismatch Airline Plug / Jack	03S102-K100
 All dimensions are in mm; tolerances according to ISO 2768 m-H Interface According to Mechanically compatible with IEC 60169-23 RPC-2.92 and SMA Documents Application note AN001 "Calibration Services" Documentation This Part is delivered with: USB Stick with S2p data file of the reference measurement values.Calibration Certificate as PDF file. Calibration Certificate Details see "Declaration of calibration" options.		
Rosenberger Hochfrequenztechnik GmbH & Co. KG P.O.Box 1260 D-84526 Tittmoning Germany www.rosenberger.de		Tel. : +49 8684 18-0 Email : info@rosenberger.de
		Page 1 / 3

Material and plating

Connector parts

Center conductor
Outer conductor
Coupling nut

Material

CuBe
Brass
Stainless steel

Plating

Gold, min. 1.27 µm, over chemical nickel
Gold, min. 1.27 µm, over chemical nickel
Passivated

Mechanical data

Mating cycles ≥ 500
Maximum torque 1.70 Nm
Recommended torque 0.90 Nm
Nominal Airline dimensions at 23 °C:
- Diameter outer conductor 3.500 mm
- Diameter inner conductor 50 Ω section 1.520 mm
- Diameter inner conductor 25 Ω section 2.307 mm
- Length outer conductor 100.00 mm
- Length inner conductor 100.00 mm
- Length difference ≤ 0.04 mm
(outer conductor – inner conductor)
- Length 25 Ω section 75.00 mm

Electrical verification standard

This Mismatch Airline is designed as an electrical verification standard. Reference measurement values (calibration results) for transmission and reflection are included. Connected to a calibrated VNA the actual measured transmission and reflection values can be compared to the reference measurement values and the quality of the VNA calibration can be evaluated.

Environmental data

Operating temperature range¹ +20 °C to +26 °C
Storage temperature range 0 °C to +50 °C
RoHS compliant

1. This range is a recommendation. However, the mismatch airline can be used in a wider range.
Any temperature change from 23 °C results in dimensional changes.

Dieses Dokument ist urheberrechtlich geschützt • This document is protected by copyright • Rosenberger Hochfrequenztechnik GmbH & Co. KG
RF_35/09.14/6.2

Technical Data Sheet				Rosenberger											
RPC-3.50		Mismatch Airline Plug / Jack		03S102-K100											
Declaration of calibration options Factory Calibration Standard delivery for this calibration standard includes a Factory Calibration. The Calibration Certificate issued reports individual calibration results. Reflection results are traceable to national / international standards. A S2p data file with the reference measurement values is included. Accredited Calibration Not available. For further, more detailed information see application note AN001 on the Rosenberger homepage. Calibration interval <table><tr><td>Recommendation</td><td>12 months</td></tr></table> Packing <table><tr><td>Standard</td><td>1 pce in box</td></tr><tr><td>Weight</td><td>20.1 g/pce</td></tr><tr><td>Center conductor</td><td>loose in an acrylic glass tube</td></tr></table>								Recommendation	12 months	Standard	1 pce in box	Weight	20.1 g/pce	Center conductor	loose in an acrylic glass tube
Recommendation	12 months														
Standard	1 pce in box														
Weight	20.1 g/pce														
Center conductor	loose in an acrylic glass tube														
While the information has been carefully compiled to the best of our knowledge, nothing is intended as representation or warranty on our part and no statement herein shall be construed as recommendation to infringe existing patents. In the effort to improve our products, we reserve the right to make changes judged to be necessary.															
Draft		Date		Rev.		Engineering change number									
Herbert Babinger		17.04.15		e00		15-1558									
Approved		Date		Name		Date									
Martin Moder		09.11.15		Manfred Ruf		09.11.15									
Rosenberger Hochfrequenztechnik GmbH & Co. KG P.O.Box 1260 D-84526 Tittmoning Germany www.rosenberger.de				Tel. : +49 8684 18-0 Email : info@rosenberger.de			Page 3 / 3								

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Rosenberger:](#)

[03S102-K100](#)