


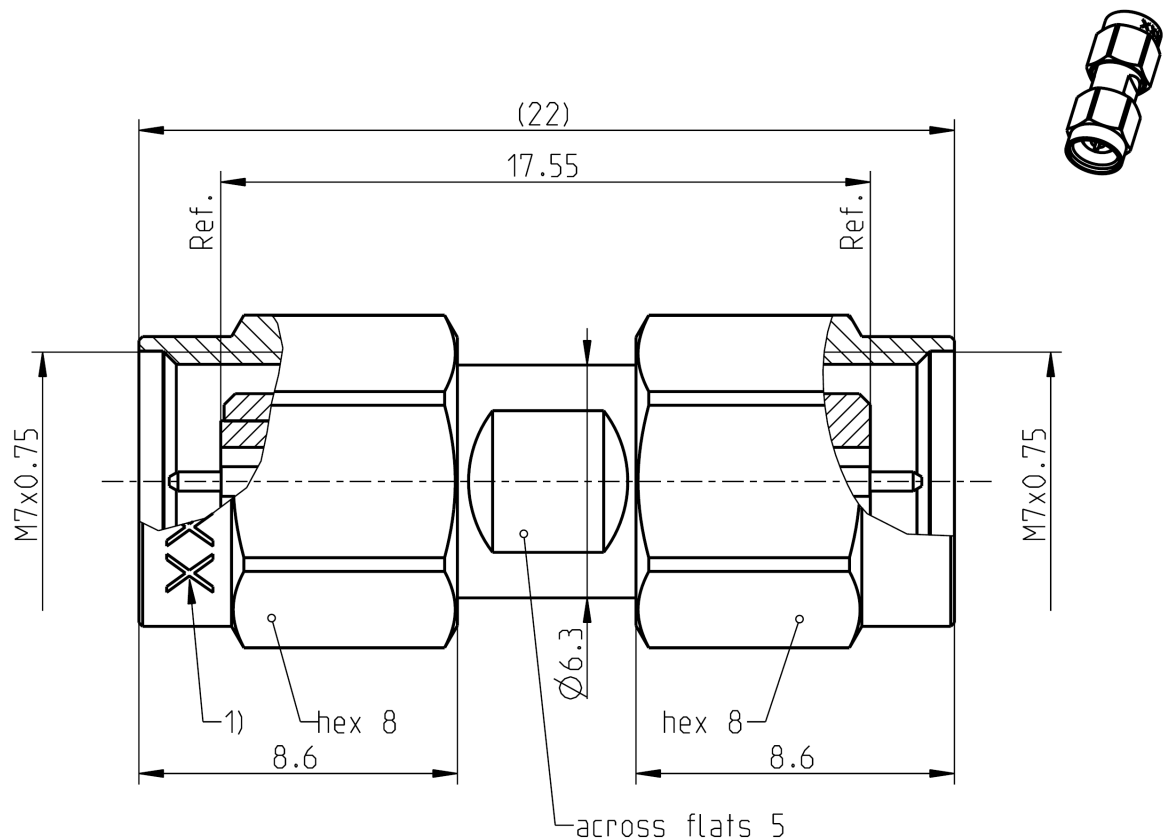

1) Marking: DC to 70 GHz

All dimensions are in mm; tolerances according to ISO 2768 m-H

InterfaceAccording to
Mechanically compatible withIEC 61169-32
RPC-2.40**Documents**

N/A

Material and plating**Connector parts**Center contact
Outer contact
Coupling nut
Dielectric**Material**Beryllium copper
Stainless steel
Stainless steel
PEEK**Plating**Gold, min. 1.27 µm, over chemical nickel
Passivated
Passivated

TECHNICAL DATA SHEET

Rosenberger

RPC-1.85

ADAPTOR
PLUG - PLUG

08S121-S00S3

Electrical data

Impedance	50 Ω
Frequency	DC to 70 GHz
Return loss	≥ 17 dB, DC to 70 GHz
Insertion loss	≤ 0.05 x $\sqrt{f(\text{GHz})}$ dB
Insulation resistance	≥ 5 GΩ
Center contact resistance	≤ 4.0 mΩ
Outer contact resistance	≤ 2.5 mΩ
Test voltage	500 V rms
Working voltage	150 V rms
RF-leakage	≥ 100 dB up to 1 GHz

Mechanical data

Mating cycles	≥ 500
Center contact captivation	≥ 20 N
Coupling test torque	1.65 Nm
Recommended torque	0.80 Nm to 1.10 Nm

Environmental data

Temperature range	-40°C to +85°C
Thermal shock	IEC 61169-1, Subclause 9.4.4
Corrosion	IEC 61169-1, Subclause 9.4.6
Vibration	IEC 61169-1, Subclause 9.3.3
Shock	IEC 61169-1, Subclause 9.3.14
Moisture resistance	IEC 61169-1, Subclause 9.4.3
2002/95/EC (RoHS)	compliant

Tooling

N/A

Suitable cables

N/A

Packing

Standard	1 pce in box
Weight	5.6 g/pce

While the information has been carefully compiled to the best of our knowledge, nothing is intended as representation or warranty on our part and no statement herein shall be construed as recommendation to infringe existing patents. In the effort to improve our products, we reserve the right to make changes judged to be necessary.

Draft	Date	Approved	Date	Rev.	Engineering change number	Name	Date
Herbert Babinger	25/08/04	Roland Neuhauser	05/06/12	d00	12-0375	Maik Knoll	05/06/12

Rosenberger Hochfrequenztechnik GmbH & Co. KG
P.O.Box 1260 D-84526 Tittmoning Germany
www.rosenberger.de

Tel.: +49 8684 18-0
Fax: +49 8684 18-499
email: info@rosenberger.de

Page

2 / 2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Rosenberger:](#)

[08S121-S00S3](#)