
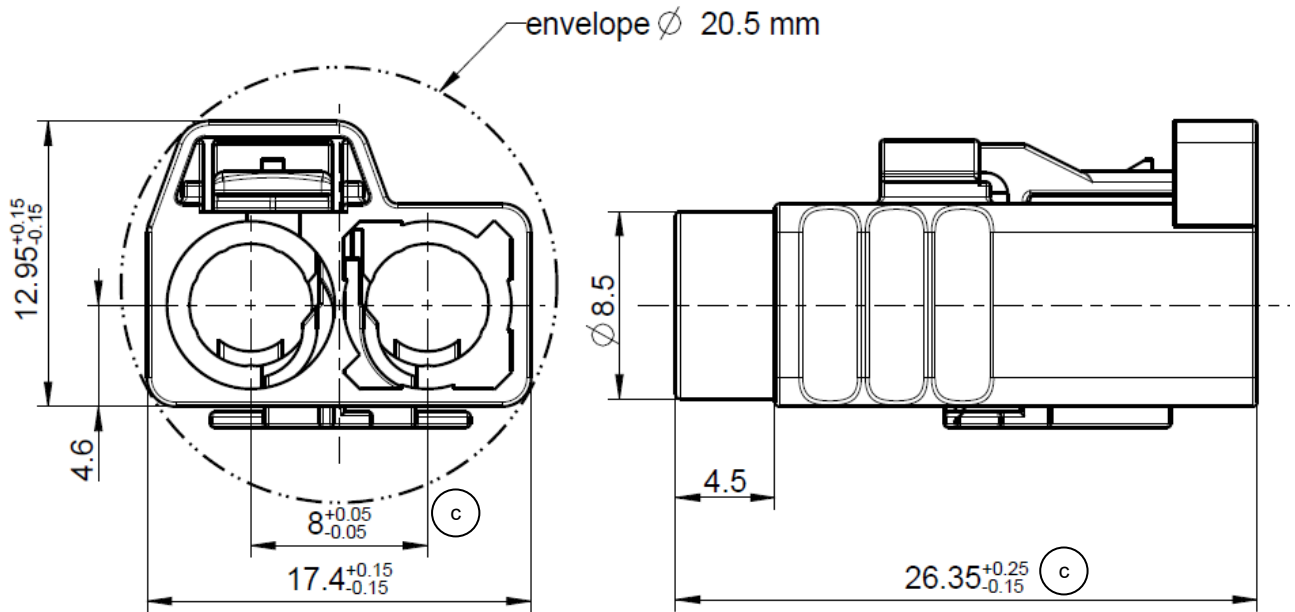


secondary lock in pre-position delivered

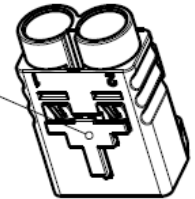

All dimensions are in mm; tolerances according to ISO 2768 m-H
 Y = Part number has to be accomplished by codification

Interface

According to DIN 72594-1

Material

Housing PBT-GF10 (b)
 Secondary Lock PBT-GF10

Mechanical data

Mating cycles ≥ 25
 Retention force latch ≥ 110 N
 Retention force primary lock ≥ 80 N
 Retention force secondary lock ≥ 60 N
 Coding efficiency ≥ 40 N

Dieses Dokument ist urheberrechtlich geschützt • This document is protected by copyright • Rosenberger Hochfrequenztechnik GmbH & Co. KG

RF_35/05.10/6.2

Environmental data

| | |
|--------------------------------|------------------------|
| Temperature range | -40°C to +105°C |
| Thermal shock | DIN 72594-2 clause 6.2 |
| Temperature and humidity | DIN 72594-2 clause 6.3 |
| Vibration and mechanical shock | DIN 72594-2 clause 6.1 |
| Dry heat | DIN 72594-2 clause 6.4 |
| RoHS | compliant |

Application

Applicable e.g. for following connectors: 59K130-1xx*¹⁾, 59K13D-1xx*¹⁾, 59K13F-1xx*¹⁾, 59K16A-1xx*¹⁾, 59K16B-1xx*¹⁾


 












^{*1)} -xx for all available cable variations
-xxx

Packing

Standard 500 pcs in box, 750 pcs in reusable container b
Weight 2.55 g/pce

Coding

Part Number has to be accomplished by codification

| Coding | Color | RAL | Part-Number |
|---|----------------|-----------|-----------------------------|
|  A | black | sim. 9005 | 59Z115-000-A |
|  B | white | sim. 9001 | 59Z115-000-B |
|  C | blue | sim. 5005 | 59Z115-000-C |
|  D | bordeauxviolet | sim. 4004 | 59Z115-000-D |
|  E | green | sim. 6002 | 59Z115-000-E |
|  F | brown | sim. 8011 | 59Z115-000-F |
|  G | grey | sim. 7031 | 59Z115-000-G |
|  H | violet | sim. 4003 | 59Z115-000-H |
|  I | beige | sim. 1001 | 59Z115-000-I |
|  K | curry | sim. 1027 | 59Z115-000-K |
|  L | carmine red | sim. 3002 | 59Z115-000-L* ²⁾ |
|  M | pastel orange | sim. 2003 | 59Z115-000-M* ²⁾ |
|  N | pastel green | sim. 6019 | 59Z115-000-N* ²⁾ |
|  Z | waterblue | sim. 5021 | 59Z115-000-Z |
| | traffic purple | sim. 4006 | secondary lock |

*²⁾ available on request

Change History

| Rev. | Date | Change |
|------|----------|---|
| b00 | 26.10.17 | Changed Standard: From "500 pcs in box" to "500 pcs in box, 750 pcs in reusable container" |
| c01 | 14.02.20 | Add tolerance $\pm 0,05$, adjust tolerance from ± 0.25 to $+0.25-0.15$ |

Dieses Dokument ist urheberrechtlich geschützt • This document is protected by copyright • Rosenberger Hochfrequenztechnik GmbH & Co. KG

While the information has been carefully compiled to the best of our knowledge, nothing is intended as representation or warranty on our part and no statement herein shall be construed as recommendation to infringe existing patents. In the effort to improve our products, we reserve the right to make changes judged to be necessary.

| Draft | Date | Approved | Date | Rev. | Engineering change number | Name | Date |
|--------------|----------|----------|----------|------|---------------------------|-----------------|----------|
| F. Neureiter | 14.06.10 | F. Danzl | 14.02.20 | c01 | 20-0155 | S. Guggenberger | 14.02.20 |

| | | |
|--|--|---------------|
| Rosenberger Hochfrequenztechnik GmbH & Co. KG P.O.Box 1260 D-84526 Tittmoning Germany www.rosenberger.de | Tel. : +49 8684 18-0 Email : info@rosenberger.de | Page 3 / 3 |
|--|--|---------------|

RF_35/05.10/6.2

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Rosenberger:](#)

[59Z115-000C](#) [59Z115-000G](#) [59Z115-000A](#) [59Z115-000H](#) [59Z115-000F](#) [59Z115-000Z](#) [59Z115-000E](#) [59Z115-000B](#)
[59Z115-000D](#) [59Z115-000I](#)