
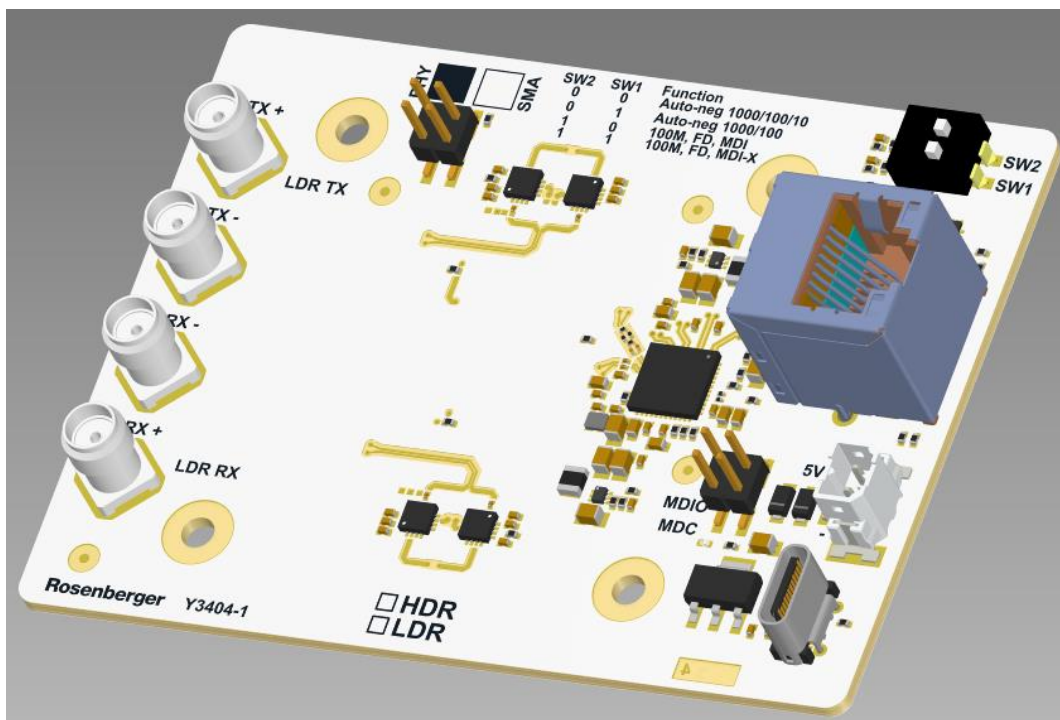


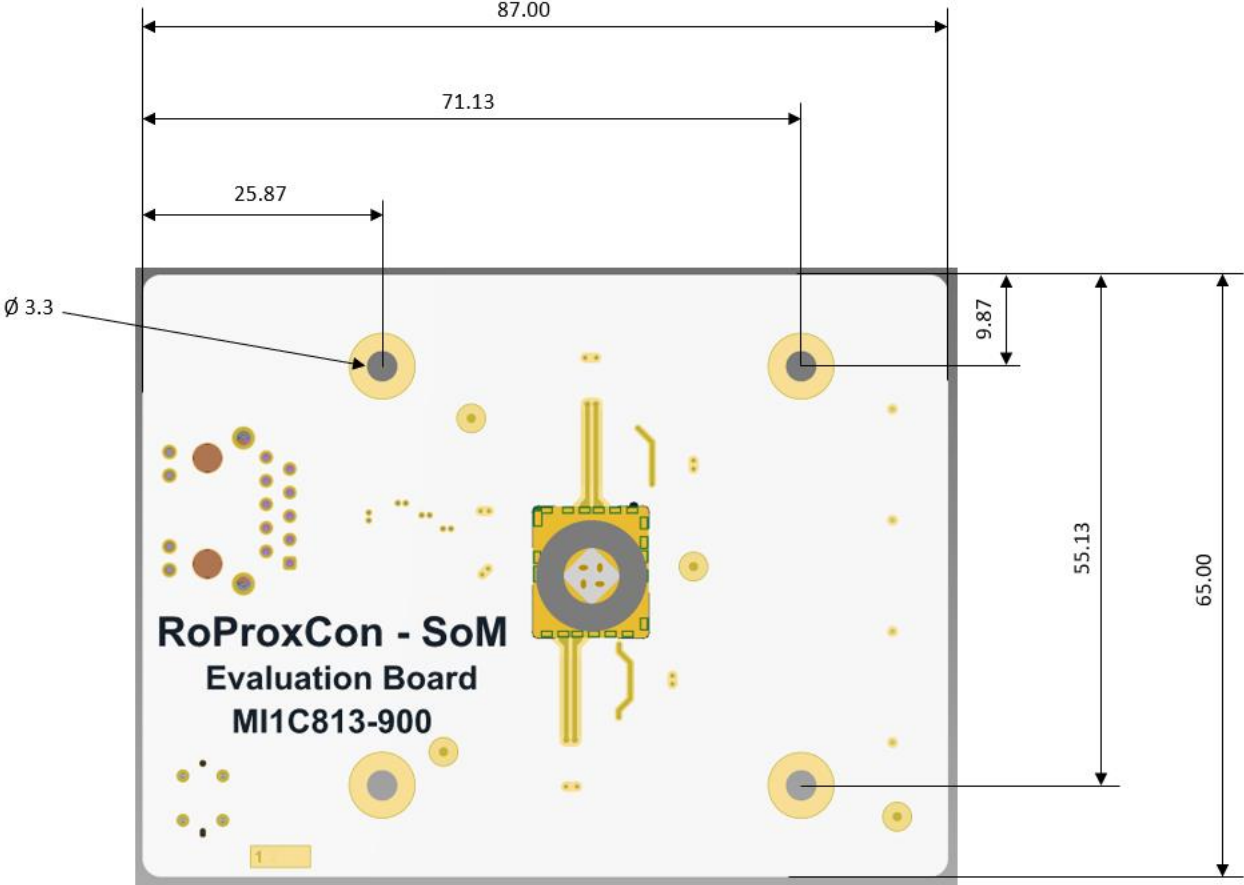

RFB00035/10.11.2023/6.5
Dieses Dokument ist urheberrechtlich geschützt • This document is protected by copyright • Rosenberger Hochfrequenztechnik GmbH & Co. KG

TECHNICAL DATA SHEET - DRAFT		Rosenberger
MI	RoProxCon – SoM Evaluation Board	MI1C813-900
Dimension 		
All dimensions in mm		
Documents UserManual BA_en_RoProxCon_EvaluationBoard_MI1C813-900		
Electrical Power supply 5V or USB-C Data rate max. 3.125 Gbit/s via SMA Max. 1.25 Gbit/s via RJ45 (10/100/1000 Base-T with auto-neg) Protocol/Signal Signal 8b10b coded / 400mVpp via SMA 10/100/1000 Base-T with auto-neg Ethernet via RJ45		
Rosenberger Hochfrequenztechnik GmbH & Co. KG P.O.Box 1260 D-84526 Tittmoning Germany www.rosenberger.com		Tel.: +49 8684 18-0 Fax.: +49 8684 18-499 email: info@rosenberger.com
		Page 2 / 3

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Rosenberger:](#)

[MI1C813-900](#)