


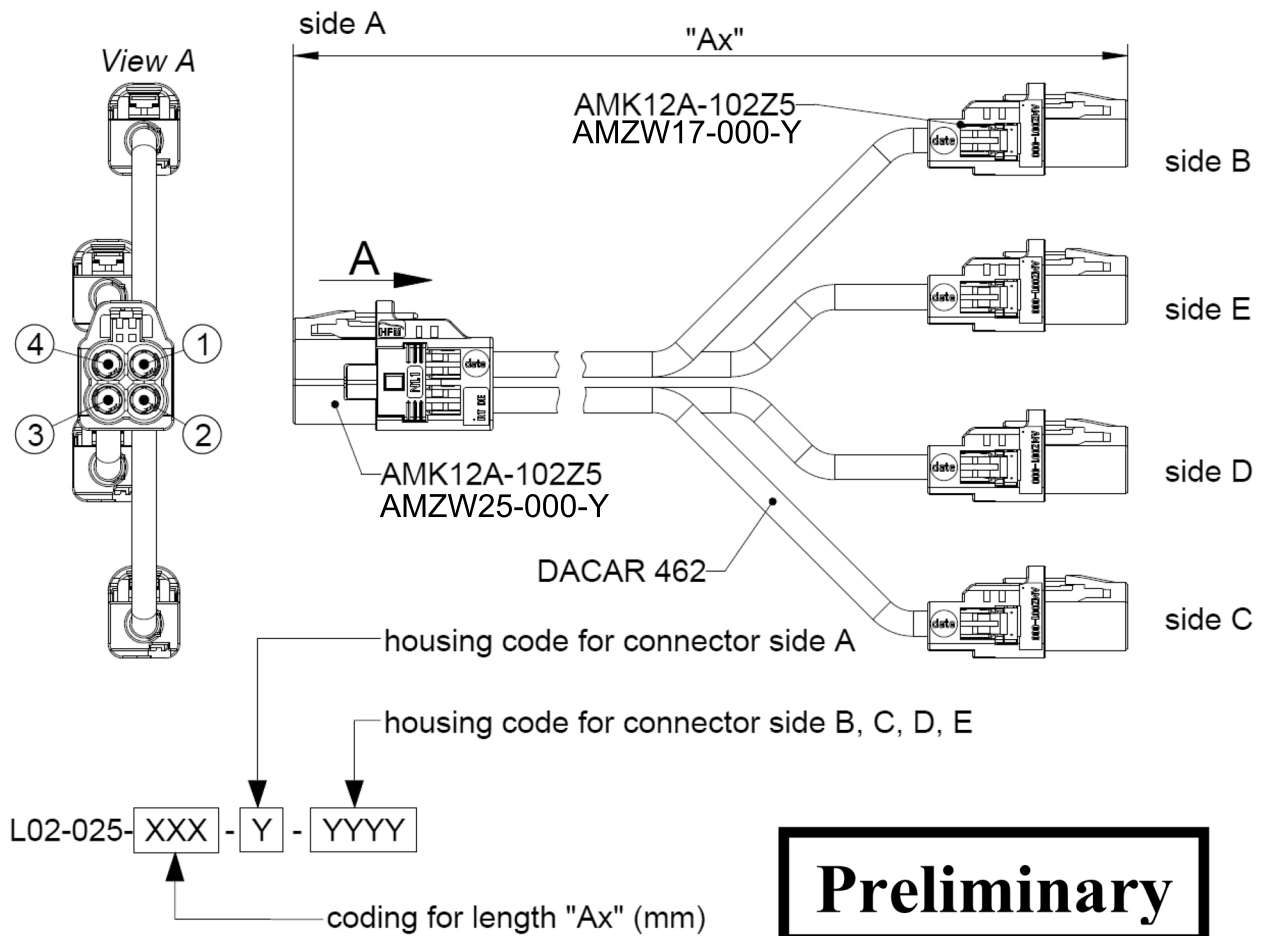

<i>cable</i>	<i>cable type</i>	<i>pinning view A</i>	<i>pinning view B</i>
Pos. 1	Dacar 462	1	side B
Pos. 2	Dacar 462	4	side E
Pos. 3	Dacar 462	3	side D
Pos. 4	Dacar 462	2	side C

cable length		
range of length "Ax" (mm)	≤ 300	> 300
tolerance for "Ax"	± 3 mm	± 1 %

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Rosenberger:](#)

[L02-025-1000-Z-ZZZZ](#)