

Shielded Stacked 2x2 RJ45

8P/8C Shielded Stacked and Ganged 2x2 RJ45 Ethernet Connectors



Product Features:


- Shielded RJ45 2x2 Connectors
- Minimum of 750 Mating Cycles
- Multiple Gold Contact Plating Options
- DWV - 1500VAC Contact to Shield
- Current Rating - 1.5A
- Voltage Rating - 125V
- UL94V-0 Flammability Rating

| Part Number | Mechanical | Contact Gold Plating (min) | Operating Temp Range | LED Color (L/R) |
|-----------------|------------|----------------------------|----------------------|-----------------|
| HCJ22-802SK | A | 6μ" | -40°C to +85°C | None |
| HCJ22-804SK | A | 30μ" | -40°C to +85°C | None |
| HCJ22-805SK | A | 50μ" | -40°C to +85°C | None |
| HCJ22-802SK-L11 | B | 6μ" | -40°C to +85°C | Green/Green |
| HCJ22-804SK-L11 | B | 30μ" | -40°C to +85°C | Green/Green |
| HCJ22-805SK-L11 | B | 50μ" | -40°C to +85°C | Green/Green |
| HCJ22-802SK-L12 | B | 6μ" | -40°C to +85°C | Green/Yellow |
| HCJ22-804SK-L12 | B | 30μ" | -40°C to +85°C | Green/Yellow |
| HCJ22-805SK-L12 | B | 50μ" | -40°C to +85°C | Green/Yellow |
| HCJ22-802SK-L21 | B | 6μ" | -40°C to +85°C | Yellow/Green |
| HCJ22-804SK-L21 | B | 30μ" | -40°C to +85°C | Yellow/Green |
| HCJ22-805SK-L21 | B | 50μ" | -40°C to +85°C | Yellow/Green |


Notes:

1. Alternate footprints, shielding, and LED colors available. Please contact the factory for additional information.
2. Part specific datasheets available upon request.

A - Mechanical (w/o LEDs)

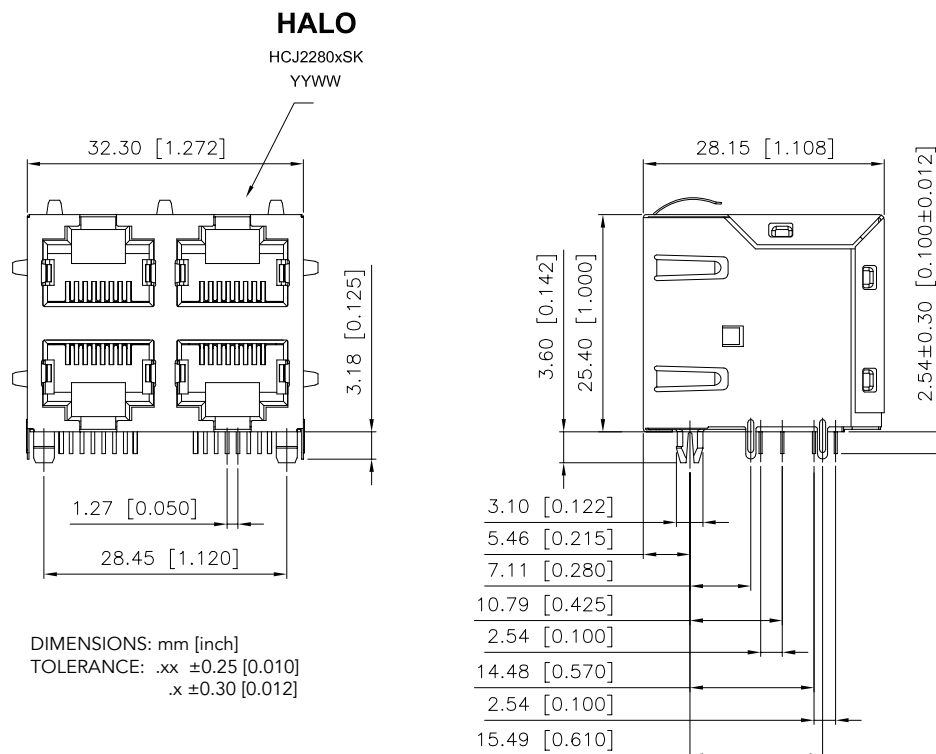


A - PCB Layout (w/o LEDs)

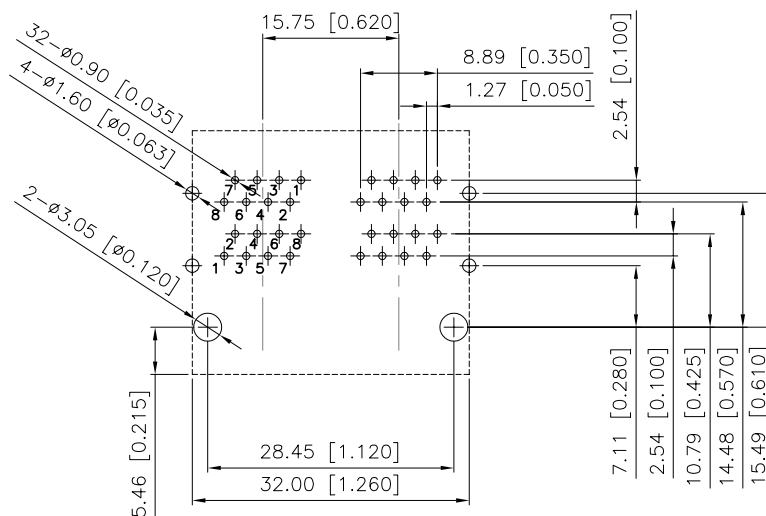


Recommended PCB Layout (Top View)
Dimensional Tolerance: ±0.08 [0.003]


B - Mechanical (w/ LEDs)

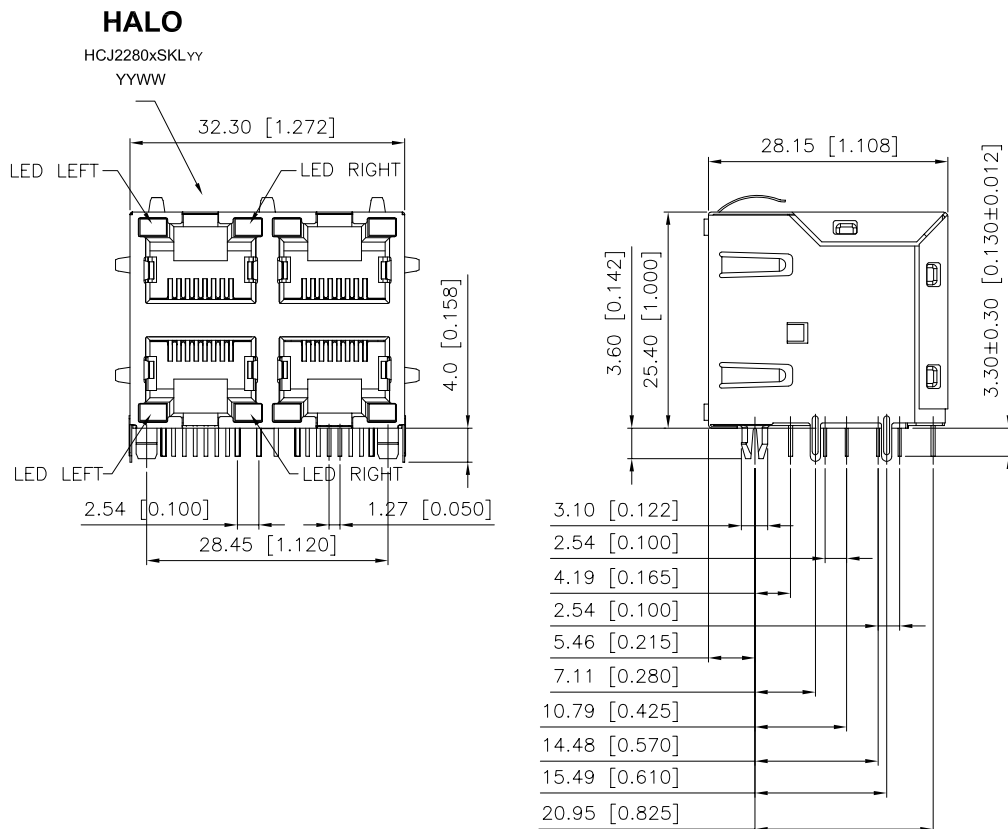

B - PCB Layout (w/ LEDs)

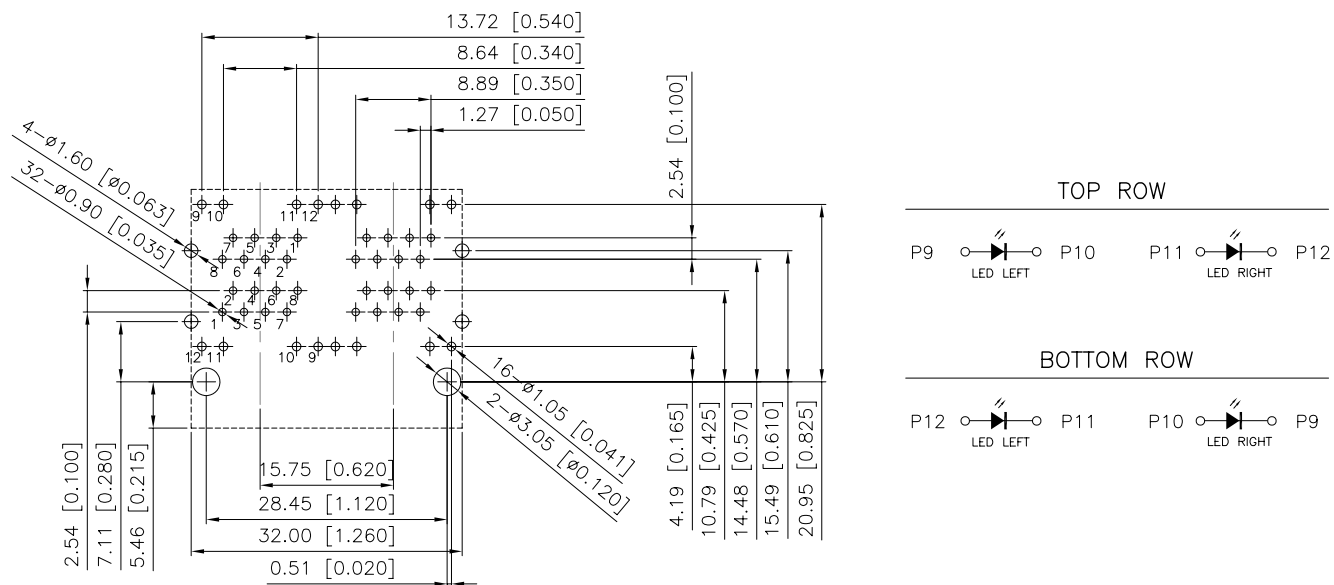

Recommended PCB Layout (Top View)
Dimensional Tolerance: ± 0.08 [0.003]

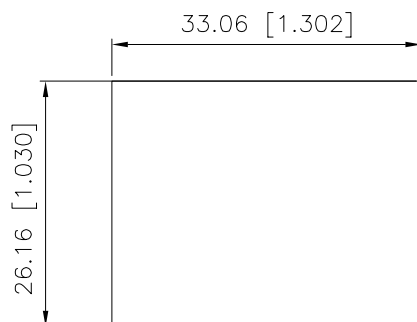

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

HALO Electronics:

[HCJ22-805SK-L21](#) [HCJ22-804SK-L11](#) [HCJ22-804SK-L12](#) [HCJ22-804SK-L21](#) [HCJ22-805SK](#) [HCJ22-805SK-L11](#)
[HCJ22-805SK-L12](#) [HCJ22-802SK](#) [HCJ22-802SK-L11](#) [HCJ22-802SK-L12](#) [HCJ22-802SK-L21](#) [HCJ22-804SK](#)