




120V – 230V AC Input (rated)
12V / 24V DC Output (nominal)

Specified for use with Storm AXS access control products this robust, steel encased, switch mode power supply is rated for continuous high performance applications.

The Storm AXS power supply includes an integrated battery charger with intelligent battery state monitoring. This power supply is designed specifically for use in access control and building security applications.

(Please note: Battery not included).

The supply includes two power outputs. One provides continuous power for system use. The second is configurable for either 'fail safe' or 'fail secure' operation in response to activation of a fire alarm system.

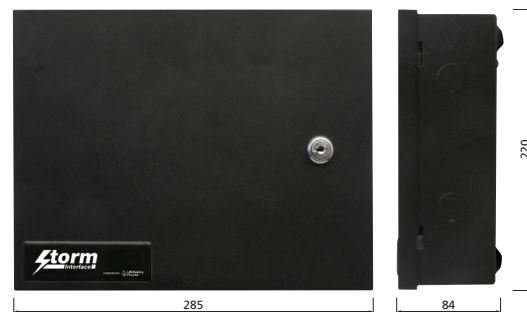

All dimensions in mm

- 12V/6A or 24V/3A output
- 120/230V AC input
- Integral fire alarm interface
- Integral battery condition monitoring
- Data link connection
- Enhanced output noise immunity
- Dual DC outputs (continuous and re-settable)
- 2 Year limited warranty
- Designed to meet UL294/cUL/CE



Whilst every effort is made to ensure details are correct at time of print, specifications are subject to change without notice.



For more information & to order:
www.storm-interface.com

Storm Interface products include technology protected by international patents and design registration. All rights reserved. Storm is a trademark of Keymat Technology Ltd. Storm Interface is a trading name of Keymat Technology Ltd.

DEPS030 June 2015

Designed & produced by NIK Design Ltd
www.nikdesign.co.uk



FM 39602

Specified for use with Storm AXS Access Control Solutions

Storm-AXS StrikeMaster keypads
 Storm-AXS Electro-magnetic door locks
 Storm-AXS Touch-free exit switch
 Storm-AXS Emergency override switch (break glass)

Part Numbers

DR2KW20, DR2KT20, DE1KT10
 DEL600, DEL1200, DEG1200
 DEEX010
 DEEM010



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Storm Interface:](#)

[DEPS0303](#)