

WORLDWIDE



Sixcess

a new generation of lamp




Sixcess

- Long Life expectancy
- Rugged solid-state construction for shock & vibration resistance
- Reduced Running costs
- Low Power Consumption
- Reduce down time
- Looks identical to 6S6 day or night
- Indoor or outdoor, sealed sockets



Available
in 12V &
24V

Sixcess Specification	
Size & Socket:	6S6 Candelabra (E12) form factor
Color Temperature:	3100 Kelvin average
Power Consumption:	<1.0 watts
Input Voltage:	Part# 2410F73-12V 12VDC/VAC +/-10%
	Part# 2410F73-24V 24VDC/VAC +/-10%
Lumen Output Type:	8.0 Flux (1m)
Lumen Depreciation	Typ. 15k hours with 70% lumen maintenance
Minimum	15k hours with 50% Lumen maintenance. ave. amb temp of 80 deg F. over lamp life
Operational Temp Range:	110 deg F max. 15 deg min. Environmentally sealed
Lens:	Polycarbonate material with UV inhibitors

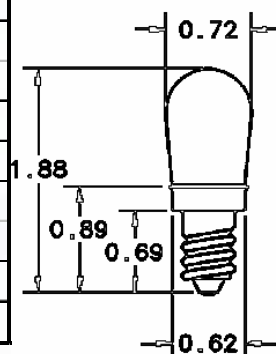

Note: Do not subject unit to transients or spikes > 50Volts peak



making LED's easy...



America:
CML Innovative Technologies, Inc.
147 Central Avenue
Hackensack - NJ 07601 - USA
Tel: 1-201-489 - 8989
Fax: 1-201-489 - 6911
e-mail: america@cml-it.com

Europe:
CML Technologies GmbH & Co. KG
Robert-Bunsen-Str. 1
67098 Bad Dürkheim - GERMANY
Tel: +49 (0) 6322 9567-0
Fax: +49 (0) 6322 9567-88
e-mail: europe@cml-it.com

Asia:
CML Innovative Technologies, Inc.
61 Aida Street
Singapore 459975
Tel: (65) 9630 - 5003
e-mail: asia@cml-it.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Chicago Miniature:](#)

[2410F73-24V](#)