


DDR4 Value Memory

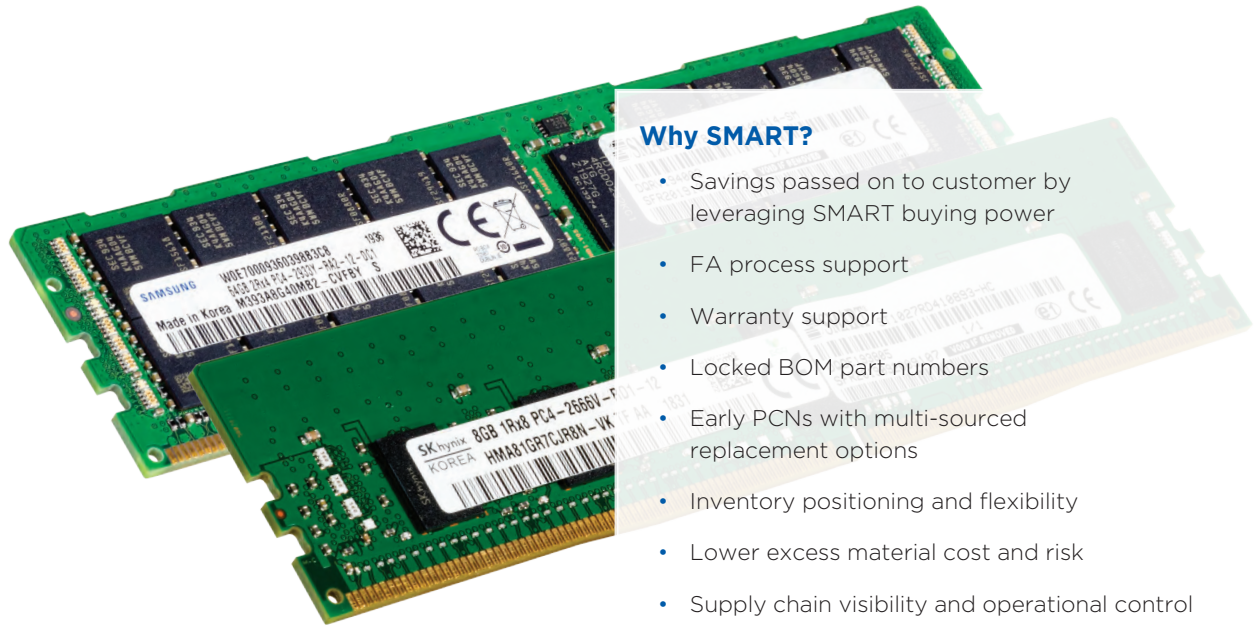

SMART offers a wide lineup of Value Memory; cost-effective Tier 1 ODM JEDEC-standard DDR4 memory modules designed for budget conscious applications. SMART is able to provide this series of Value Memory modules by leveraging its more than \$1 Billion of purchasing power with its supplier relationships. SMART buys its finished lineup of commodity-class memory modules directly from Samsung[®], Micron[®] and Hynix[®].

Applications

- For industry segments using mainstream JEDEC-standard modules

Additional Services

- Full support from SMART as your DRAM supplier
- Cost effective and economic solutions
- Quick turnarounds on time-sensitive jobs
- Most common Value Memory products:
16GB, 32GB RDIMMs 4GB, 8GB, 16GB Non-ECC SO-DIMMs
- SMTL test reports (per customer request)
- Labeled with original ODM and SMART labels

DDR4 Memory Modules

288-PIN - DDR4 RDIMM (Standard Height & VLP)							
SMART Part Number	Density	Height (mm)	Module Config	Device Config	Speed	Voltage	Temp
ST3277RD440444-SM	256GB	31.25	32Gb x72	4Gx4	2933MT/s	1.2V	0°C to +70°C
ST1637RD440444-SM	128GB	31.25	16Gb x72	4Gx4	2933MT/s	1.2V	0°C to +70°C
ST1637RD420423-SB	128GB	31.25	16Gb x72	2Gx4	2666MT/s	1.2V	0°C to +70°C
SH1637RD420492-SB	128GB	31.25	16Gb x72	2Gx4	2400MT/s	1.2V	0°C to +70°C
ST8197RD440414-SM	64GB	31.25	8Gb x72	4Gx4	2933MT/s	1.2V	0°C to +70°C
ST8197RD420423-SB	64GB	31.25	4Gb x72	2Gx4	2666MT/s	1.2V	0°C to +70°C
ST8197RD440493-SM	64GB	31.25	8Gb x72	4Gx4	2666MT/s	1.2V	0°C to +70°C
ST4097RD420425-SD	32GB	31.25	4Gb x72	2Gx4	3200MT/s	1.2V	0°C to +70°C
ST4097RD440425-SA	32GB	31.25	4Gb x72	4Gx4	3200MT/s	1.2V	0°C to +70°C
ST4097RD420414-HC	32GB	31.25	4Gb x72	2Gx4	2933MT/s	1.2V	0°C to +70°C
ST4097RD420414-SC	32GB	31.25	4Gb x72	2Gx4	2933MT/s	1.2V	0°C to +70°C
STI4097RD420493-SC	32GB	31.25	4Gb x72	2Gx4	2666MT/s	1.2V	-40°C to +85°C
ST4097RD420493-HC	32GB	31.25	4Gb x72	2Gx4	2666MT/s	1.2V	0°C to +70°C
ST4097RD420493-SC	32GB	31.25	4Gb x72	2Gx4	2666MT/s	1.2V	0°C to +70°C
STB4097RD420493-SC	32GB	31.25	4Gb x72	2Gx4	2666MT/s	1.2V	0°C to +70°C
ST2047RD420425-SD	16GB	31.25	2Gb x72	2Gx4	3200MT/s	1.2V	0°C to +70°C
ST2047RD410814-SC	16GB	31.25	2Gb x72	1Gx8	2933MT/s	1.2V	0°C to +70°C
ST2047RD420414-HC	16GB	31.25	2Gb x72	2Gx4	2933MT/s	1.2V	0°C to +70°C
ST2047RD420414-SC	16GB	31.25	2Gb x72	2Gx4	2933MT/s	1.2V	0°C to +70°C
STB2047RD420414-SC	16GB	31.25	2Gb x72	2Gx4	2933MT/s	1.2V	0°C to +70°C
STI2047RD410893-SC	16GB	31.25	2Gb x72	1Gx8	2666MT/s	1.2V	-40°C to +85°C
STI2047RD420493-SC	16GB	31.25	2Gb x72	2Gx4	2666MT/s	1.2V	-40°C to +85°C
ST2047RD410893-HC	16GB	31.25	2Gb x72	1Gx8	2666MT/s	1.2V	0°C to +70°C
ST2047RD410893-SC	16GB	31.25	2Gb x72	1Gx8	2666MT/s	1.2V	0°C to +70°C
ST2047RD420493-HC	16GB	31.25	2Gb x72	2Gx4	2666MT/s	1.2V	0°C to +70°C
ST2047RD420493-SC	16GB	31.25	2Gb x72	2Gx4	2666MT/s	1.2V	0°C to +70°C
STB2047RD420472-SC	16GB	31.25	2Gb x72	2Gx4	2400MT/s	1.2V	0°C to +70°C
ST1027RD410814-SD	8GB	31.25	1Gb x72	1Gx8	2933MT/s	1.2V	0°C to +70°C
ST1027RD410893-HC	8GB	31.25	1Gb x72	1Gx8	2666MT/s	1.2V	0°C to +70°C
288-PIN - DDR4 ECC UDIMM							
SMART Part Number	Density	Height (mm)	Module Config	Device Config	Speed	Voltage	Temp
ST4097UD420814-SA	32GB	31.25	4Gb x72	2Gx8	2933MT/s	1.2V	0°C to +70°C
ST4097UD420893-SM	32GB	31.25	4Gb x72	2Gx8	2666MT/s	1.2V	0°C to +70°C
ST1027UD410893-HC	8GB	31.25	1Gb x72	1Gx8	2666MT/s	1.2V	0°C to +70°C
288-PIN - DDR4 non-ECC UDIMM							
SMART Part Number	Density	Height (mm)	Module Config	Device Config	Speed	Voltage	Temp
ST4096UD420893-SM	32GB	31.25	4Gb x64	2Gx8	2666MT/s	1.2V	0°C to +70°C
ST2046UD410893-HC	16GB	31.25	2Gb x64	1Gx8	2666MT/s	1.2V	0°C to +70°C
ST2046UD410893-SC	16GB	31.25	2Gb x64	1Gx8	2666MT/s	1.2V	0°C to +70°C
ST1026UD410893-HC	8GB	31.25	1Gb x64	1Gx8	2666MT/s	1.2V	0°C to +70°C
ST1026UD410893-SC	8GB	31.25	1Gb x64	1Gx8	2666MT/s	1.2V	0°C to +70°C
ST1026UD410872-HC	8GB	31.25	1Gb x64	1Gx8	2400MT/s	1.2V	0°C to +70°C
ST5126UD451693-HC	4GB	31.25	512Mb x64	512Mx16	2666MT/s	1.2V	0°C to +70°C
ST5126UD451693-SC	4GB	31.25	512Mb x64	512Mx16	2666MT/s	1.2V	0°C to +70°C
260-PIN - DDR4 ECC SO-DIMM							
SMART Part Number	Density	Height (mm)	Module Config	Device Config	Speed	Voltage	Temp
STI4097SO420893-SM	32GB	30	4Gb x72	2Gx8	2666MT/s	1.2V	-40°C to +85°C
ST4097SO420893-SM	32GB	30	4Gb x72	2Gx8	2666MT/s	1.2V	0°C to +70°C
ST2047SO410814-SD	16GB	30	2Gb x72	1Gx8	2933MT/s	1.2V	0°C to +70°C
STI2047SO410893-SD	16GB	30	2Gb x72	1Gx8	2666MT/s	1.2V	-40°C to +85°C
ST2047SO410893-SD	16GB	30	2Gb x72	1Gx8	2666MT/s	1.2V	0°C to +70°C
ST1027SO410893-HC	8GB	30	1Gb x72	1Gx8	2666MT/s	1.2V	0°C to +70°C

DDR4 Memory Modules Continued

260-PIN - DDR4 Non-ECC SO-DIMM							
SMART Part Number	Density	Height (mm)	Module Config	Device Config	Speed	Voltage	Temp
ST4096SO420893-SM	32GB	30	4Gb x64	2Gx8	2666MT/s	1.2V	0°C to +70°C
STI2046SO410893-SC	16GB	30	2Gb x64	1Gx8	2666MT/s	1.2V	-40°C to +85°C
STI2046SO410893-SD	16GB	30	2Gb x64	1Gx8	2666MT/s	1.2V	-40°C to +85°C
ST2046SO410893-HC	16GB	30	2Gb x64	1Gx8	2666MT/s	1.2V	0°C to +70°C
ST2046SO410893-SC	16GB	30	2Gb x64	1Gx8	2666MT/s	1.2V	0°C to +70°C
ST2046SO410893-SD	16GB	30	2Gb x64	1Gx8	2666MT/s	1.2V	0°C to +70°C
STI1026SO410893-SC	8GB	30	1Gb x64	1Gx8	2666MT/s	1.2V	-40°C to +85°C
STI1026SO410893-SD	8GB	30	1Gb x64	1Gx8	2666MT/s	1.2V	-40°C to +85°C
ST1026SO410893-HC	8GB	30	1Gb x64	1Gx8	2666MT/s	1.2V	0°C to +70°C
ST1026SO410893-HJ	8GB	30	1Gb x64	1Gx8	2666MT/s	1.2V	0°C to +70°C
ST1026SO410893-SC	8GB	30	1Gb x64	1Gx8	2666MT/s	1.2V	0°C to +70°C
ST1026SO410893-SD	8GB	30	1Gb x64	1Gx8	2666MT/s	1.2V	0°C to +70°C
ST5126SO451693-HC	4GB	30	512Mb x64	512Mx16	2666MT/s	1.2V	0°C to +70°C
ST5126SO451672-HC	4GB	30	512Mb x64	512Mx16	2400MT/s	1.2V	0°C to +70°C
ST5126SO451693-SC	4GB	30	512Mb x64	512Mx16	2400MT/s	1.2V	0°C to +70°C
288-PIN - DDR4 LRDIMM							
SMART Part Number	Density	Height (mm)	Module Config	Device Config	Speed	Voltage	Temp
ST3277LR440444-SM	256GB	31.25	32Gb x72	4Gx4	2933MT/s	1.2V	0°C to +70°C
ST1637LR440414-SM	128GB	31.25	16Gb x72	4Gx4	2933MT/s	1.2V	0°C to +70°C
ST1637LR420402-HM	128GB	31.25	16Gb x72	2Gx4	2400MT/s	1.2V	0°C to +70°C
ST8197LR420414-SC	64GB	31.25	8Gb x72	2Gx4	2933MT/s	1.2V	0°C to +70°C

Contact information

Corporate Headquarters/North America: T: (+1) 800-956-7627 • T: (+1) 510-623-1231 • F: (+1) 510-623-1434 • E: info@smartm.com

Customer Service: T: (+1) 510-623-1231 • E: customers@smartm.com

Latin America: T: (+55) 11 4417-7200 • E: sales.br@smartm.com

EMEA: T: (+44) 0 7826-064-745 • E: sales.euro@smartm.com

Asia/Pacific: T: (+65) 6678-7670 • E: sales.asia@smartm.com

For more information, please visit: www.smartm.com



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

SMART Modular Technologies:

[ST1026UD410893-SC](#) [ST1026SO410893-SD](#) [ST2046SO410893-SD](#) [STI1026SO410893-SD](#) [STI2046SO410893-SD](#)
[ST2046UD410893-SC](#) [ST5126SO451693-SC](#)