

Co-Solvent Low Evaporating Flux Remover 1L

Product Highlights


Powerful Co-Solvent Flux Remover
Low Evaporating
Effective Cleaning of densely populated assemblies

Environmentally-Friendly
Low Ozone Depletion, Low Toxicity
RoHS 3 and REACH compliant

Specifications

Boiling Range:	150°C
Flash Point:	82°C
Liquid Density:	1.011 g/cm ³ (at 20°C)
Aspect:	Colorless Liquid
Water Content:	<0.1%
Aromatic Compounds:	<0.1%
NVR:	<0.01g/100ml
Net Weight:	1.011kg
Net Volume:	1L
Packaging:	1L Jug (1.011kg net weight)*
	*Packaged and Sold by Weight

Co-solvent De-fluxing Process:

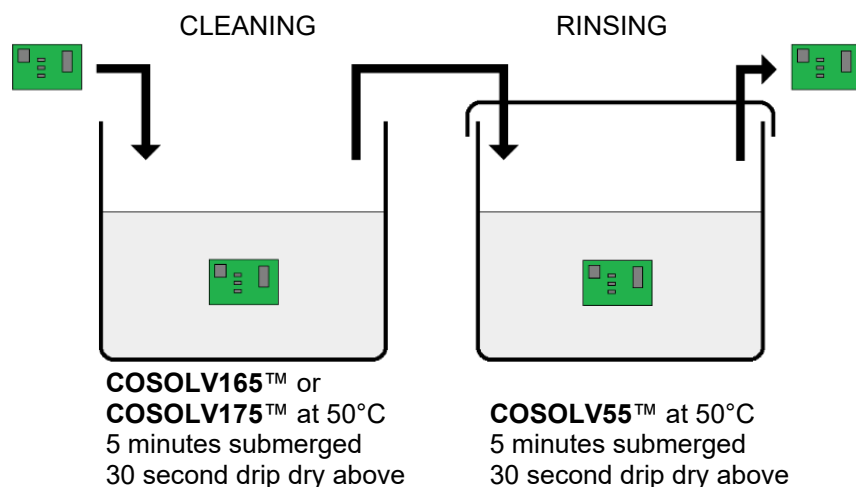

Storage and Handling

Store refrigerated or at room temperature 3-25°C (37-77°F).

Transportation

This product has no shipping restrictions. Shipping below 0°C (32°F) or above 25°C (77°F) for normal transit times by ground or air will not impact this product's stated shelf life.

Conforms to the following Industry Standards:

RoHS 3 Directive (EU) 2015/863:

Yes

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Chip Quik:

COSOLV165-1L