

## 5cc syringe (with piston, front cover, rear cover, two tips, plunger) – Qty 1

### Product Highlights

OEM CHIPQUIK 5cc syringe (with plunger)  
Quantity 1

### Specifications

Optical Density (OD): 0.036  
Light Transmittance (% Transmittance): 94.786  
(Light Source Test Wavelength: 380nm to 760nm)

### Includes:

syringe x1  
piston x1  
front cover x1  
rear cover x1  
conical plastic dispensing tip (18 gauge) x1  
straight stainless steel dispensing tip (18 gauge) x1  
plunger x1  
plunger retainer x1

### Packaging:

All parts come unassembled.



### Compatible with all CHIPQUIK dispensing tips:

| Part Number | Tip Type                                   | Tip Gauge           | Tip Orifice Internal Diameter (mm) | Tip Orifice Internal Diameter (inches) |
|-------------|--------------------------------------------|---------------------|------------------------------------|----------------------------------------|
| SMDTA30     | Straight Stainless Steel / Conical Plastic | Multiple (15 sizes) | Multiple (15 sizes)                | Multiple (15 sizes)                    |
| SMDTA200    | Straight Stainless Steel                   | Multiple (8 sizes)  | Multiple (8 sizes)                 | Multiple (8 sizes)                     |
| SMDN-16G    | Straight Stainless Steel                   | 16                  | 1.194 mm                           | 0.0470 inches                          |
| SMDN-18G    | Straight Stainless Steel                   | 18                  | 0.838 mm                           | 0.0330 inches                          |
| SMDN-19G    | Straight Stainless Steel                   | 19                  | 0.686 mm                           | 0.0270 inches                          |
| SMDN-20G    | Straight Stainless Steel                   | 20                  | 0.603 mm                           | 0.0237 inches                          |
| SMDN-21G    | Straight Stainless Steel                   | 21                  | 0.514 mm                           | 0.0202 inches                          |
| SMDN-22G    | Straight Stainless Steel                   | 22                  | 0.413 mm                           | 0.0163 inches                          |
| SMDN-23G    | Straight Stainless Steel                   | 23                  | 0.337 mm                           | 0.0133 inches                          |
| SMDN-25G    | Straight Stainless Steel                   | 25                  | 0.305 mm                           | 0.0120 inches                          |
| SMDN-26G    | Straight Stainless Steel                   | 26                  | 0.260 mm                           | 0.0102 inches                          |
| SMDN-27G    | Straight Stainless Steel                   | 27                  | 0.210 mm                           | 0.0083 inches                          |
| SMDC-14G    | Conical Plastic                            | 14                  | 1.600 mm                           | 0.0630 inches                          |
| SMDC-16G    | Conical Plastic                            | 16                  | 1.194 mm                           | 0.0470 inches                          |
| SMDC-18G    | Conical Plastic                            | 18                  | 0.838 mm                           | 0.0330 inches                          |
| SMDC-20G    | Conical Plastic                            | 20                  | 0.603 mm                           | 0.0237 inches                          |
| SMDC-22G    | Conical Plastic                            | 22                  | 0.413 mm                           | 0.0163 inches                          |
| SMDC-25G    | Conical Plastic                            | 25                  | 0.260 mm                           | 0.0102 inches                          |

### Notes

Dispensing tip colors may differ from image

Syringe Dimensions

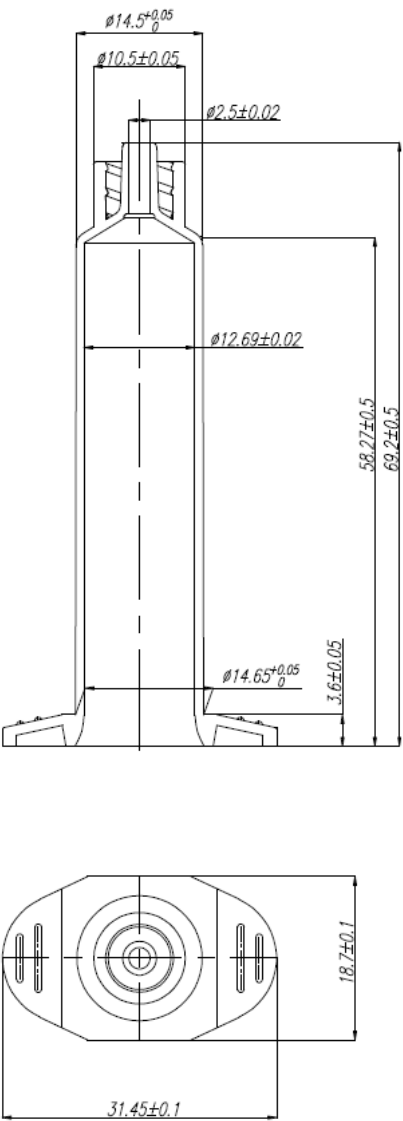


Image 1: 5cc syringe dimensions (in mm)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Chip Quik:](#)

[CQ5CC-WP-QTY1](#)