



PowerSOIC-10 / PSOP-10 / HSOP-10 to DIP-14 SMT Adapter (1.27 mm pitch, 7.5 x 9.4 mm body)

REF.	DIMENSIONS					
	mm			inches		
	MIN.	TYP.	MAX.	MIN.	TYP.	MAX.
A		10.10				
B		2.50				
C		0.75				
B2		7.40				
C2		10.50				
D		0.52				
D2		1.35				
E		1.27				
F					0.600	
G					0.100	
H					0.025	

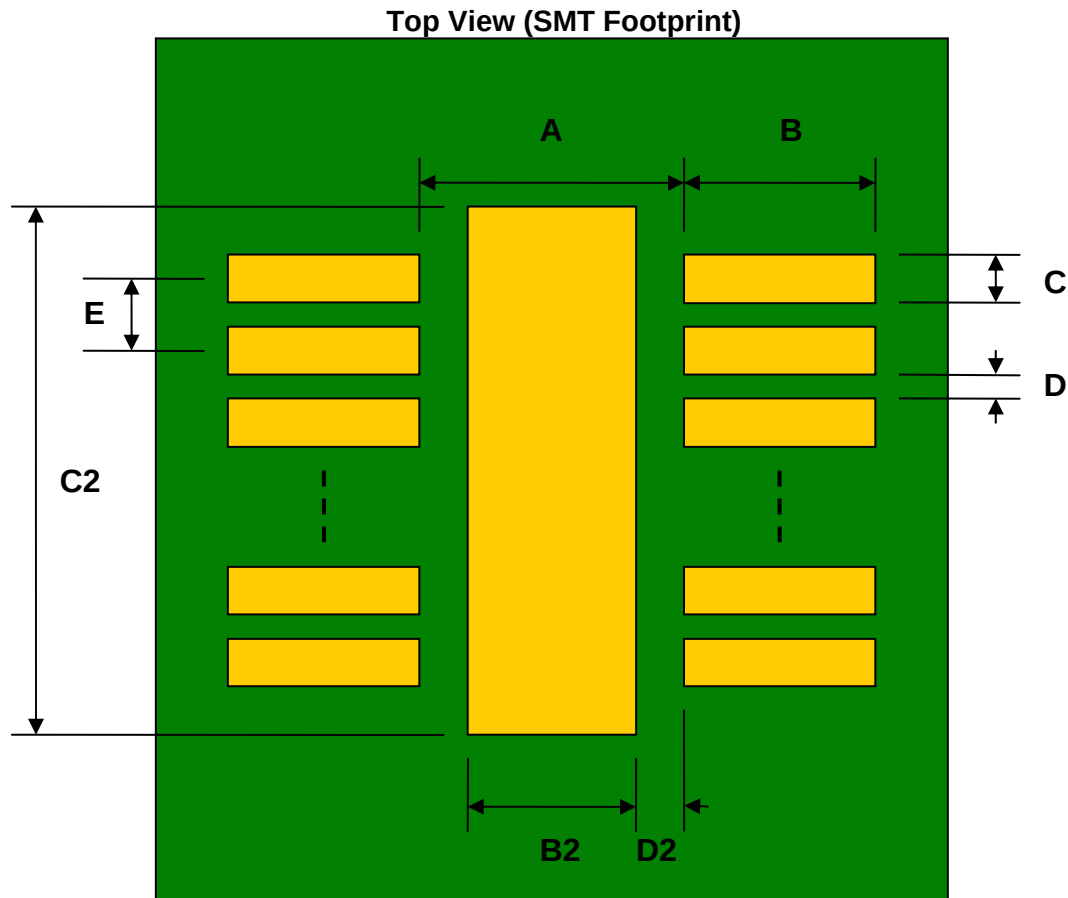


(Representative drawing only - not to scale)

Bottom View (DIP Pins)

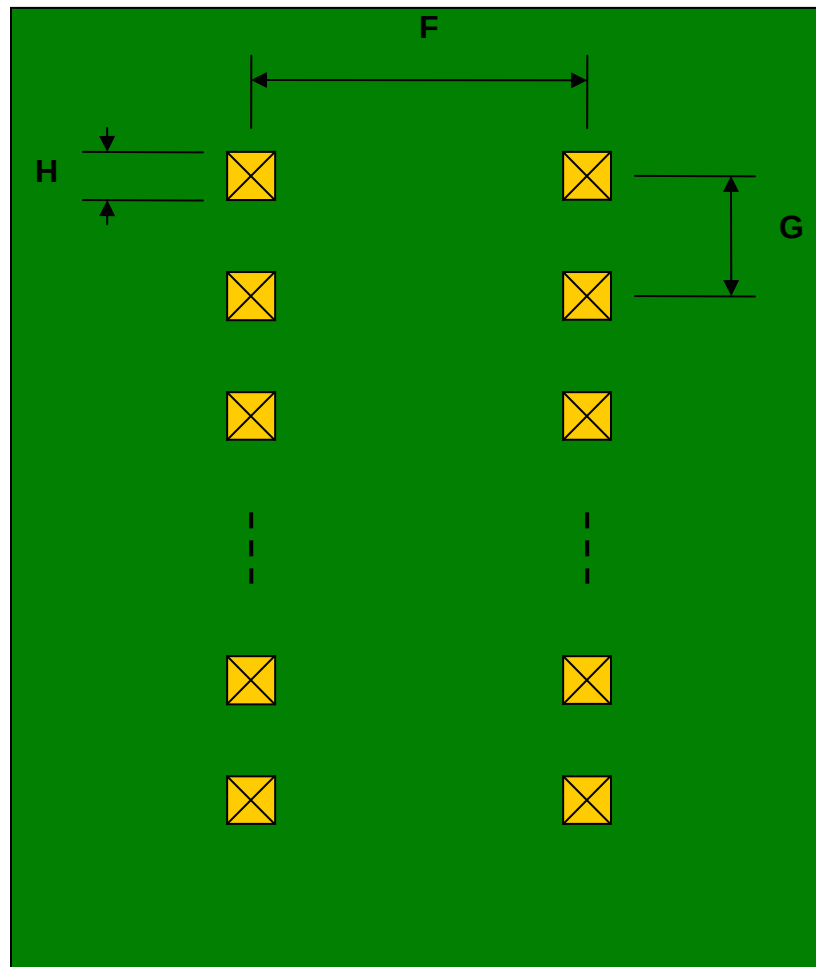

(Representative drawing only - not to scale)

Side View (DIP Pins)

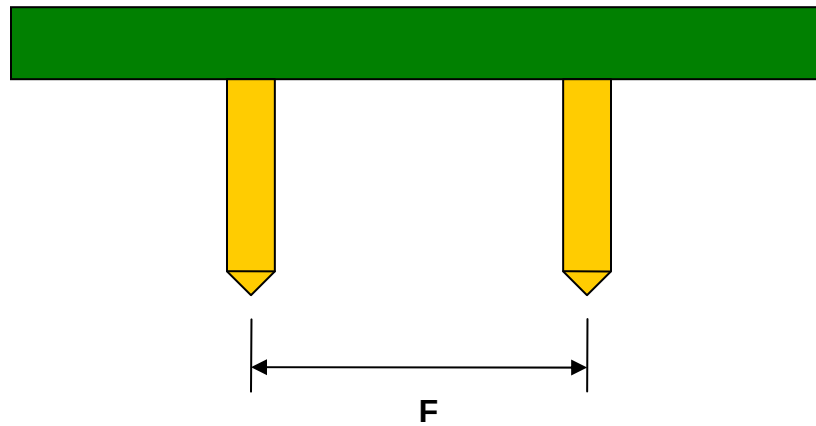

(Representative drawing only - not to scale)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Chip Quik:](#)

[IPC0050](#)